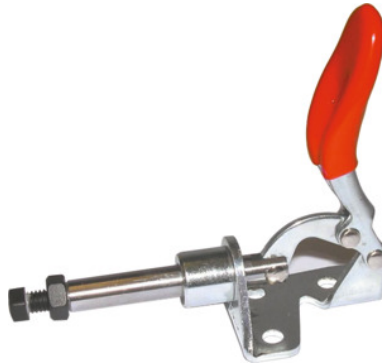


**Push-pull toggle clamp with baseplate, Type: 0****Order data**

Order number	376715 0
GTIN	4045197226778
Item class	32S

Description**Version:**

With **compound action**. Opening prevented by self-locking mechanism.

Application:

For use in special clamping fixtures for drilling, reaming, grinding, bending, welding, fitting etc.

Note:

• **Size 0 and 3 also available in stainless steel!**

Hole spacing e: 15.9 mm

Hole spacing f: 15.9 mm

Angled base width K: 27 mm

Clamping height b to centre of screw: 12.7 mm

Bore Ø d: 4.4 mm

Clamping range: 16 mm

Technical description

Bore Ø d	4.4 mm
Clamping range	16 mm
Contact screw	M4×20 mm

Angled base width K	27 mm
Hole spacing f	15.9 mm
Hole spacing e	15.9 mm
Clamping force P (pressure and traction)	450 N
Clamping height b to centre of screw	12.7 mm
Overall height H	38 mm
Overall length L	140.5 mm
Type	376715 0
Type of product	Push-pull toggle clamp