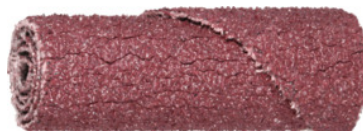


**Abrasive roll, cylindrical (A) 80 grit medium, Abrasive roll Ø× abrasive roll length: 10X38mm****Order data**

Order number	553880 10X38
GTIN	4045197524539
Item class	52E

Description**Version:**

Abrasive roll consisting of wound abrasive cloth with **Aluminium Oxide (A)**.
Cylindrical form.

Suitable for:

Abrasive roll holder No. 553835.

Suitable for:

Holder mounting Ø × overall length: 3×70

Technical description

Grit	80
Sander roller length	38 mm
Sander roller Ø	10 mm
maximum speed	26000 min ⁻¹
Grit designation	medium
Grinding media	Standard Aluminium Oxide
Grinding medium code	A
Sander roller form	cylindrical
Type of product	Abrasive roll

User data

	Suitability	V _c	ISO code
Alu Mg	suitable		
Steel < 900 N/mm ²	suitable		
Steel < 1400 N/mm ²	suitable		
Steel < 55 HRC	suitable		
Steel < 60 HRC	suitable only under restricted conditions		
INOX	suitable only under restricted conditions		
GG(G)	suitable only under restricted conditions		
CuZn	suitable		
Plastic, GRP	suitable		
Wood	suitable only under restricted conditions		
dry	suitable		

Accessories

Abrasive roll holder 6 mm shank Ø Mounting-Ø×Overall length 3X70 mm

553835 3X70