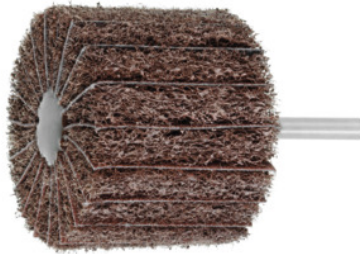


**Flap wheel Fleece / cloth, coarse, Head Ø×head width: 60X30mm****Order data**

|              |               |
|--------------|---------------|
| Order number | 554910 60X30  |
| GTIN         | 4045197241092 |
| Item class   | 52E           |

**Description****Version:**

Flap strips bonded on to the shank of the tool. Fleece is combined with abrasive cloth to **increases the abrasive effect** of the fleece. Shank Ø 6 mm.

**Application:**

For removal of dirt and oxide layers on metals as well as for matt finishing of Cr-Ni, other stainless steels, and also non-ferrous metals.

**Technical description**

|                      |                        |
|----------------------|------------------------|
| maximum speed        | 9000 min <sup>-1</sup> |
| Head width           | 30 mm                  |
| recommended speed    | 5000 min <sup>-1</sup> |
| Shank Ø              | 6 mm                   |
| Head Ø               | 60 mm                  |
| Grinding medium code | A                      |
| Grit equivalent      | 100 / 80               |
| Grit designation     | coarse                 |

|                        |            |
|------------------------|------------|
| Product name attribute | coarse     |
| Type of product        | Flap wheel |

## User data

|                                | Suitability                               | V <sub>c</sub> | ISO code |
|--------------------------------|-------------------------------------------|----------------|----------|
| Alu Mg                         | suitable                                  |                |          |
| Steel < 900 N/mm <sup>2</sup>  | suitable                                  |                |          |
| Steel < 1400 N/mm <sup>2</sup> | suitable                                  |                |          |
| Steel < 55 HRC                 | suitable                                  |                |          |
| Steel < 60 HRC                 | suitable only under restricted conditions |                |          |
| Steel < 67 HRC                 | suitable only under restricted conditions |                |          |
| INOX                           | suitable                                  |                |          |
| Ti                             | suitable only under restricted conditions |                |          |
| GG(G)                          | suitable                                  |                |          |
| CuZn                           | suitable                                  |                |          |
| Plastic, GRP                   | suitable                                  |                |          |
| Wood                           | suitable                                  |                |          |
| Paint                          | suitable only under restricted conditions |                |          |
| dry                            | suitable                                  |                |          |