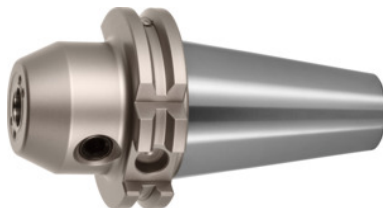


Garant

Side lock arbor Form ADB with cooling channel bores, nickel-plated, SK 40 short, Clamping Ø D1: 12mm

**Order data**

Order number	300120 12
GTIN	4045197945709
Item class	31A

Description**Version:****GARANT –**

All shanks hard turned (for smooth cutting action!). Balancing quality G 2.5 / G 25,000 rpm

With coolant supply holes that can be plugged.

Special nickel plating.

With Balluff/RFID chip bore.

Application:

For clamping tools with side flats to DIN 1835 B and DIN 6535 HB.

Optional extras:

Pull studs (PS) No. 308600 – 308806. Pull stud wrenches No. 308820; 308835.

Technical description

Spare clamping screw No. 30 9900	12
Overhang dimension A	50 mm
External Ø D	42 mm
Clamping Ø D ₁	12 mm
Adapter	SK 40 short
Standard	DIN 6359

Arbor standard	ISO 7388-1
Shape	ADB
Cooling channel bore	lockable
Balance quality G at rotational speed	G 2.5 at 25,000 rpm
Concentricity	$\leq 3 \mu\text{m}$
Machining strategy	HPC
Type of product	Side lock arbor

Accessories

Spare clamping screw for chucks with clamping $\varnothing$ D1 12 mm	309900 12
--	-----------
