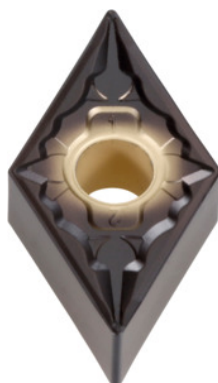


Garant**DNMG 150404, Type: HB7035-1****Order data**

Order number	250670 HB7035-1
GTIN	4045197948922
Item class	21G

Description

DNMG 150404 HB7035-1 Grade: HB7035-1

Chip breaker: SS

Cutting depth a_p : 0.3 - 2 mmFeed f : 0.1 - 0.4 mm/rev.Cutting speed v_c main application: 120 - 350 m/min**Technical description**

Cutting speed v_c main application	120 - 350 m/min
Chip breaker	SS
Tool material	Carbide
Cutting depth a_p	0.3 - 2 mm
Finishing/roughing assignment	Finishing
Corner radius	0.4 mm
Main application	P

Grade	HB7035-1
Cutting conditions	heavily interrupted
Feed f	0.1 - 0.4 mm/rev.
Coating	coated
ISO code indexable insert	DNMG 150404
Number of changes/inserts	4
Type of product	Indexable insert for turning