

CWC

WET LOCATION COMBINATION EXIT/EMERGENCY LIGHT

tradeSELECT®

FEATURES

- Includes Self-Test/Self-Diagnostics
- LED life-cycle of more than 10 years
- Fully Adjustable lamp-heads
- Quick installation
- 120/277VAC input
- Includes long-life 6VDC Nickel Cadmium battery
- Full re-charge within 24 hours
- Provided with magnetic test switch and AC-On indicator
- UL924 Wet Location Listed, 0C° to 50°C Standard Model, -20°C to 50°C with CT, "Cold Temperature" option



RELATED PRODUCTS

- [CSWEU2LED Outdoor Wet Location LED Emergency Light](#)
- [CEW - Wet Location LED Exit Sign](#)



SPECIFICATIONS

APPLICATION

- The CWC can be applied in areas that are susceptible to rain and severe moisture, such as parking decks, pools and outdoor commercial applications.

CONSTRUCTION

- The combo has an EXIT face-plate and lamp-head shield made of UV stabilized polycarbonate
- The housing is made of 5VA flame retardant polycarbonate with a white finish and is fully sealed and gasketed
- Knock-out chevrons provide directional indication

INSTALLATION

- Includes a die-cast canopy for ceiling or end mount
- Combo can also be wall mounted using the universal knock-out pattern in single-face application

ELECTRICAL

- Illumination provided by 2 each high power MR-16 based LED's driven at 3.6 watts per head

CERTIFICATIONS

- UL924 Listed for Wet Location
- NFPA 101 and NFPA 70
- OSHA

WARRANTY

- 2 year full unit warranty
- See [HLI Standard Warranty](#) for additional information

ORDERING GUIDE




| Catalog Number | Description |
|----------------|--|
| CWC1RW | Single Face, Red Letters |
| CWC2RW | Double Face, Red Letters |
| CWC1GW | Single Face, Green Letters |
| CWC2GW | Double Face, Green Letters |
| CWC1RW-CT | Single Face, Red Letters, Cold Temperature Operation |
| CWC2RW-CT | Double Face, Red Letters, Cold Temperature Operation |
| CWC1GW-CT | Single Face, Green Letters, Cold Temperature Operation |
| CWC2GW-CT | Double Face, Green Letters, Cold Temperature Operation |

Note: Photometric files available for download at www.compasslightingproducts.com

CWC

WET LOCATION COMBINATION EXIT/EMERGENCY LIGHT

DIMENSIONS

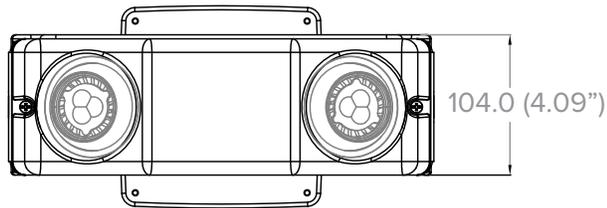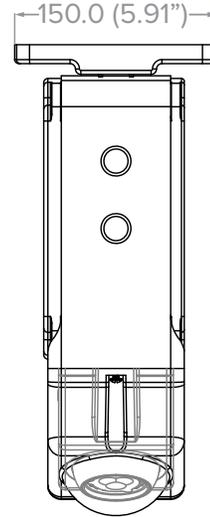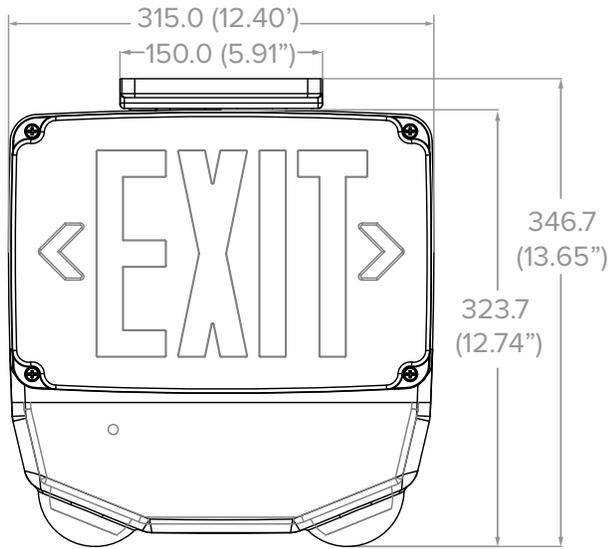

| | |
|------------------------|----------|
| Single Carton Weight | 8.4 lbs. |
| Master Carton Quantity | 4 each |

INPUT POWER REQUIREMENTS

| | Input Watts (W) | | Input Amps (A) | |
|-----------|-----------------|-------|----------------|-------|
| | 120V | 277V | 120V | 277V |
| CWC1RW | 5.2 | 5.2 | 0.05 | 0.022 |
| CWC2RW | 5.2 | 5.2 | 0.05 | 0.022 |
| CWC1GW | 5.2 | 5.1 | 0.05 | 0.021 |
| CWC2GW | 5.2 | 5.1 | 0.05 | 0.021 |
| CWC1RW-CT | 33.6 | 147.2 | 0.288 | 0.536 |
| CWC2RW-CT | 33.6 | 147.2 | 0.288 | 0.536 |
| CWC1GW-CT | 33.6 | 147.1 | 0.288 | 0.536 |
| CWC2GW-CT | 33.6 | 147.1 | 0.288 | 0.536 |