

CWR

OUTDOOR LED REMOTE HEAD

tradeSELECT®

FEATURES

- 4.8VDC Nickel Metal Hydride (NiMH) Battery
- Quick installation
- 120/277VAC input
- CJBL (low level) uses 6 LEDs for overall usage of 2 watts
- Lights re-charge within 24 hrs
- CJB uses 3 LEDs for overall usage of 2.5 watts
- UL924 listed for 10°C to 40°C (50°F to 104°F)
- Passive Infra-Red (PIR) sensor option for convenient night-light operation



RELATED PRODUCTS

Ø [CU2W - Wet Location LED Emergency Unit](#)

SPECIFICATIONS

DESCRIPTION

- The CWR single and double remote heads offer quality and value with a compact and attractive LED based outdoor remote emergency light
- Includes mounting base and lamp-heads in durable die-cast construction. Lamp-heads are fully gasketed, fully adjustable and glare-free for operation in outdoor and wet environments

- The CWR remote lamps are driven exclusively by the Compass CU2W with remote capacity.

APPLICATION

- The CWR remote heads can be applied over path of egress doors in areas affected by rain, moisture and condensation

WARRANTY

- 2 year full unit warranty
- See [HLI Standard Warranty](#) for additional information


ORDERING GUIDE

Catalog Number	Description	Voltage	Lamp Watts (Each)
CWRS	Single-head LED Remote CU2W Only, Grey Finish	9.6Vdc	1.0W
CWRD	Double-head LED Remote for CU2W Only, Grey Finish	9.6Vdc	1.0W



CU2W Emergency Light

DIMENSIONS

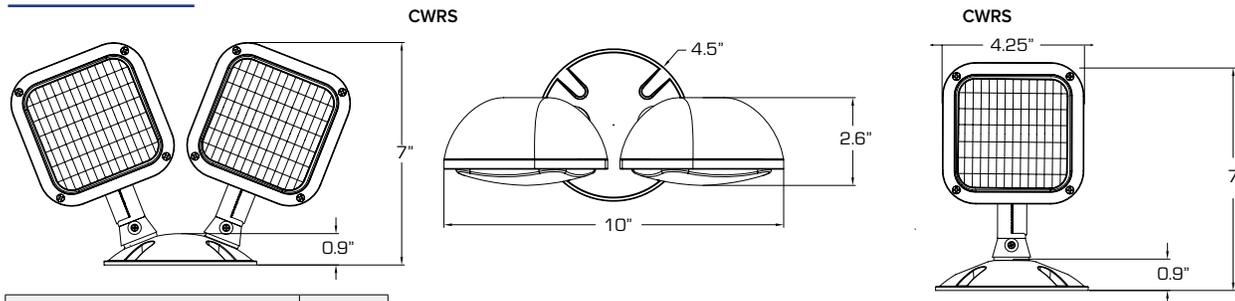

Single Carton Weight (single)	2 lbs.
Single Carton Weight (double)	2 lbs.
Master Carton Quantity	12 each

Note:
Photometric files available for download at www.compasslightingproducts.com
Outlet box must have a minimum depth of 3" (Not Included)