

# Braided Charge & Sync Cable

Do More with the World's Fastest, Most Durable Charge & Sync Cable!

Charge and Sync at maximum speed with the new Naztech Braided MFi Lightning, and Micro USB Charge & Sync Cable. Engineered to last, this ultra-durable cable is five times stronger than the competition. Say goodbye to flimsy wires that require delicate positioning. This new cable is not just tangle-free, it features reinforced stress points, braided nylon construction and thick-gauge wiring. With an incredible bend lifespan, this cable stands up to active daily use and can come along on any adventure. Enjoy the most reliable and fastest possible charging and data transfer anytime, anywhere. With Naztech's proven reputation for quality construction, top notch customer service and a lifetime warranty, there's no reason to buy any other cable.

## Features:


- Transfers Data, Music, & Pictures in Seconds
- Durable Braided Nylon Construction is 5X Stronger
- Plugs into any USB 2.0 port
- Compatible with all MFi / Micro USB devices




Charge & Sync in Seconds



Stronger than Standard Cables

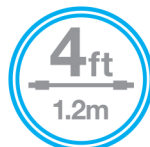

Tangle-Free Nylon Cable

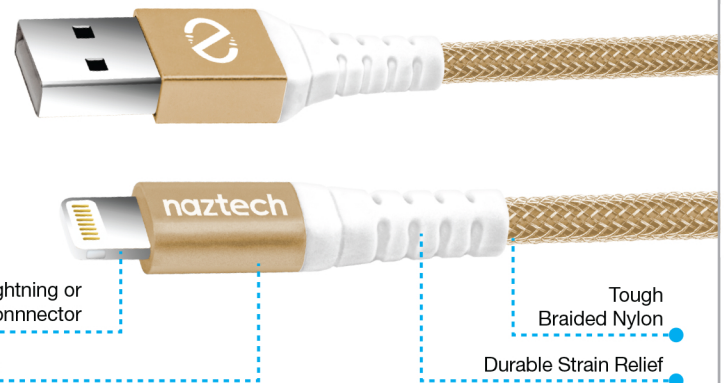

## Color Coded Packaging



Item No.	UPC	Units per Carton		Color/Type	MSRP
		Inner	Master		
13618	6 33755 13618 4	6	36	Black / Micro USB	\$24.99
13630	6 33755 13630 6	6	36	Rose Gold / Micro USB	\$24.99
13631	6 33755 13631 3	6	36	Gold / Micro USB	\$24.99
13621	6 33755 13621 4	6	36	Black / MFi Lightning	\$29.99
13632	6 33755 13632 0	6	36	Rose Gold / MFi Lightning	\$29.99
13633	6 33755 13633 7	6	36	Gold / MFi Lightning	\$29.99