

HEAVY DUTY ALL SEASON GARAGE

WG-1120-170-WT



SHORT DESCRIPTION

GP

UPC

WG-1120-170-WT	070018010	853878007073
Box Dimensions		
Box A:	77.5" x 13" x 7.5"	80.5 lbs
Box B:	79.9" x 13" x 8.2"	83.7 lbs



SPECIFICATIONS:

Frame Dimensions: 10'8" x 20'
 Center Height 9'9" Side Height 6'7"
 Tube Diameter 2" / 48mm leg & 1.5" / 38mm roof
 Roof Cables for add roof strength (images below)
 Steel Frame Powder Coated White
 Metal Footpads
 Steel Fittings thumb button lock for easy installation
 Cover: Fitted cover with leg skirts at all four corners
 Fabric: Polyethylene (PE) 170g 14x14 Weave
 Attaches with Ball Bungees (included)
 Includes Sidewall Kit / Enclosure Kit
 (2) 20' Sidewalls
 (2) 10' End walls with roll - up (3) zippered doors
 Water Resistant Cover - seams are heat-welded
 Fire Retardant CPAI-84 Sec 5 UV Resistant
 1 Year Limited Warranty
 ANCHOR KIT not included

ACCESSORIES SOLD SEPARATELY

DESCRIPTION


SHORT DESCRIPTION

GP

 
 
 
 
 

 








80" Heavy Duty Carport Canopy Roller Bag - fits (1) 10' x 20' Canopy frame and cover. 600d Polyester black fabric with wheels and carry handles	CRB-80	070019903
Ground Anchor Kit - Heavy Duty Auger Anchors - steel anchor - 8 pieces with 8 sections of rope	ANCHOR8	284009012
Replacement Ball Bungees - White Heavy Duty Elastic Straps with white ball - 25 pieces per pack	BBALL25-WT	070019902

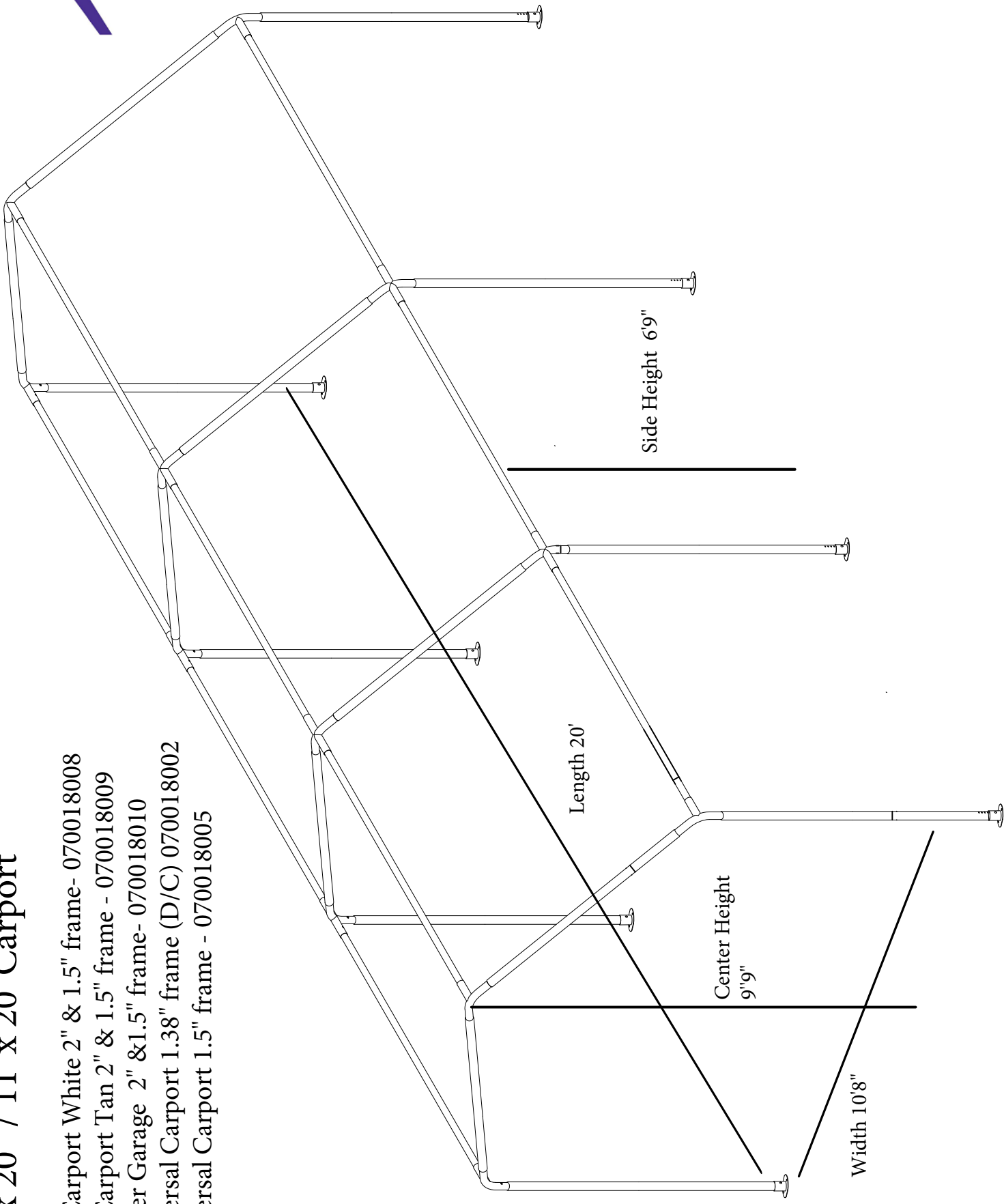10' x 20' / 11' x 20' Carport


- HD Carport White 2" & 1.5" frame- 070018008
- HD Carport Tan 2" & 1.5" frame - 070018009
- Winter Garage 2" & 1.5" frame- 070018010
- Universal Carport 1.38" frame (D/C) 070018002
- Universal Carport 1.5" frame - 070018005



   
Party Tent 10.8`X20` -Parts List-

PART	DESCRIPTION	ILLUSTRATION	QUANTITY
A	Incline Bar	400701503  61.02" Straight Pipe 1.5" diameter	8
B	Horizontal Bar	400701504  76.37" Straight Pipe 1.5" diameter	9
C	Post	400701505  76.37" Straight Pipe with swedge end 1.5" diameter	8
D	3-Way Corner	 3 Way fitting for 1.5" diameter pipe	6
E	4-Way Corner	 4 Way fitting for 1.5" diameter pipe	6
F	Base Plate	 Metal Foot pad for 1.5" diameter pipe	8
G	Bolt & Nut	 Bolt with plastic cap and nut for foot pad	8
H	Elastic Ball Strap	 Elastic ball bungees white 8"	54
I	Wirerope	 Aircraft Cable with rubber coating	4
J	Turn Buckle	 Turn Buckle	4
K	Pull-tab	 Metal Loop	4
L	Canopy Roof	070121120  Cover with Leg Skirts	1
M	End Panel	070320012  Zippered End wall	1
N	End Panel	 Solid End wall	1
O	Wall panel	070320020  20' Wide Sidewall w/ windows	2


1

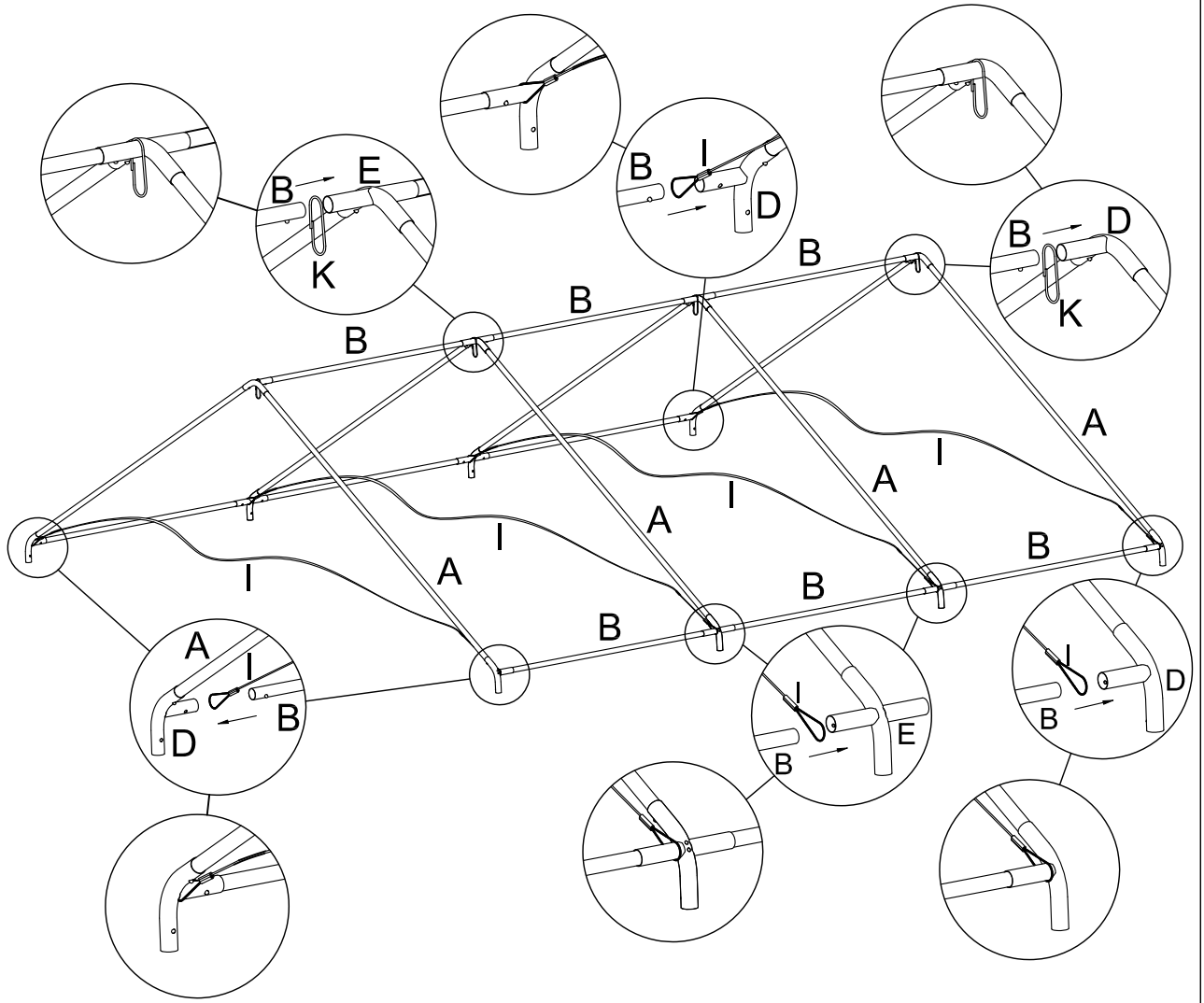


2

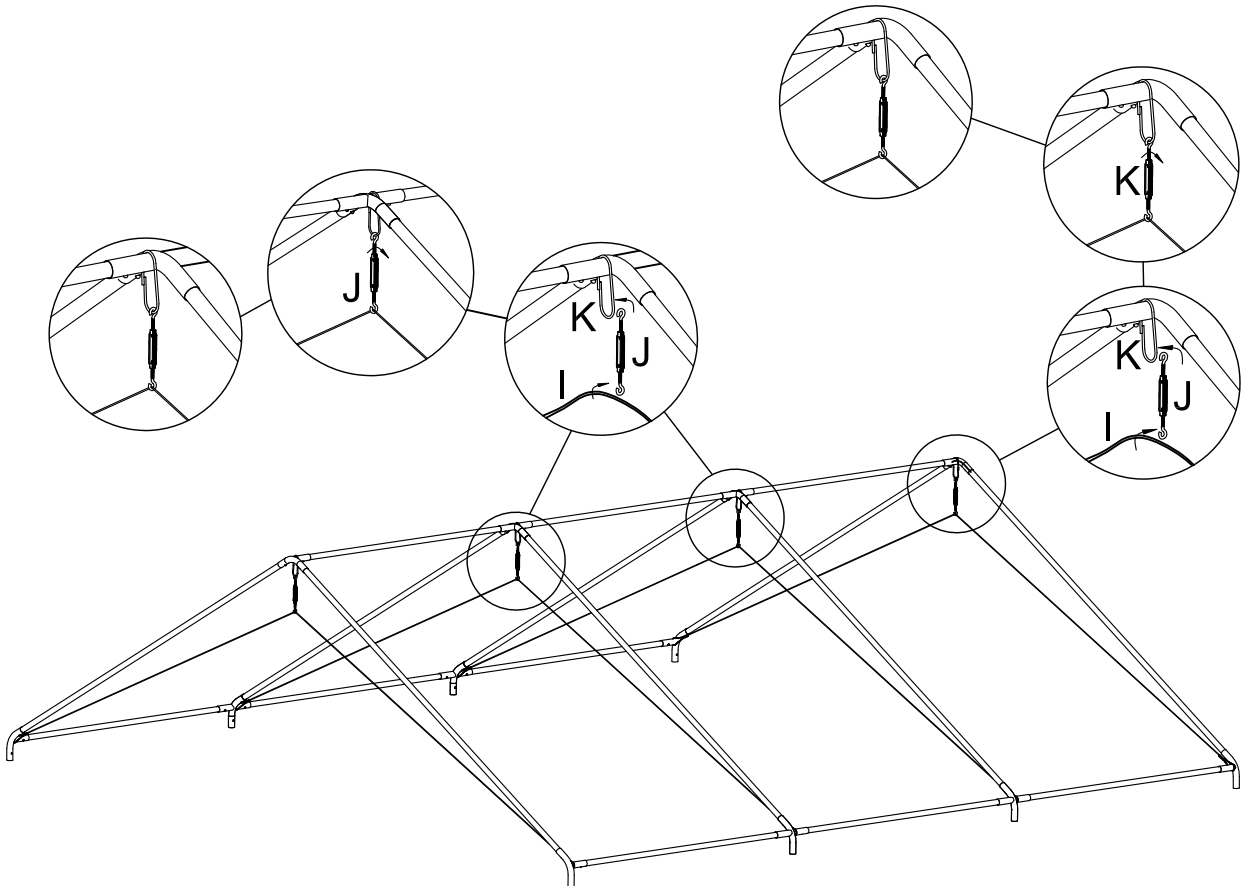


3

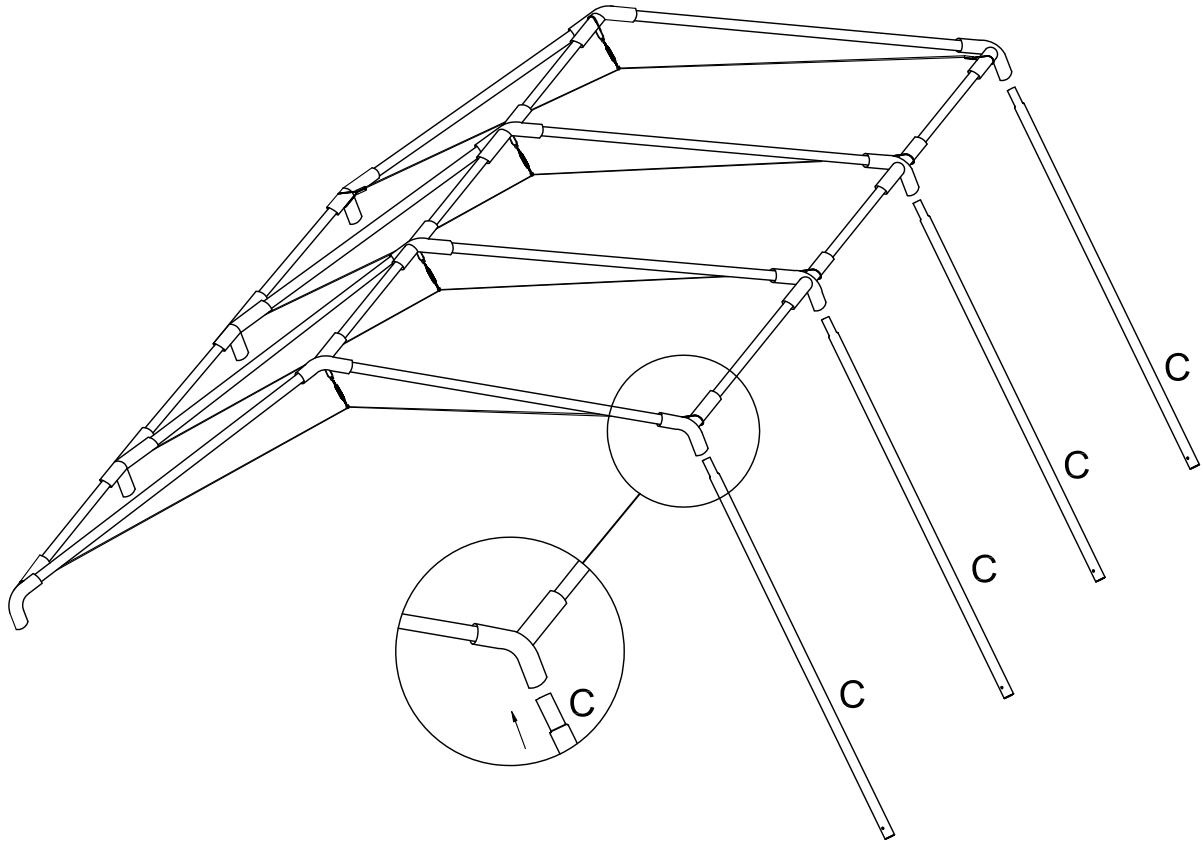


4

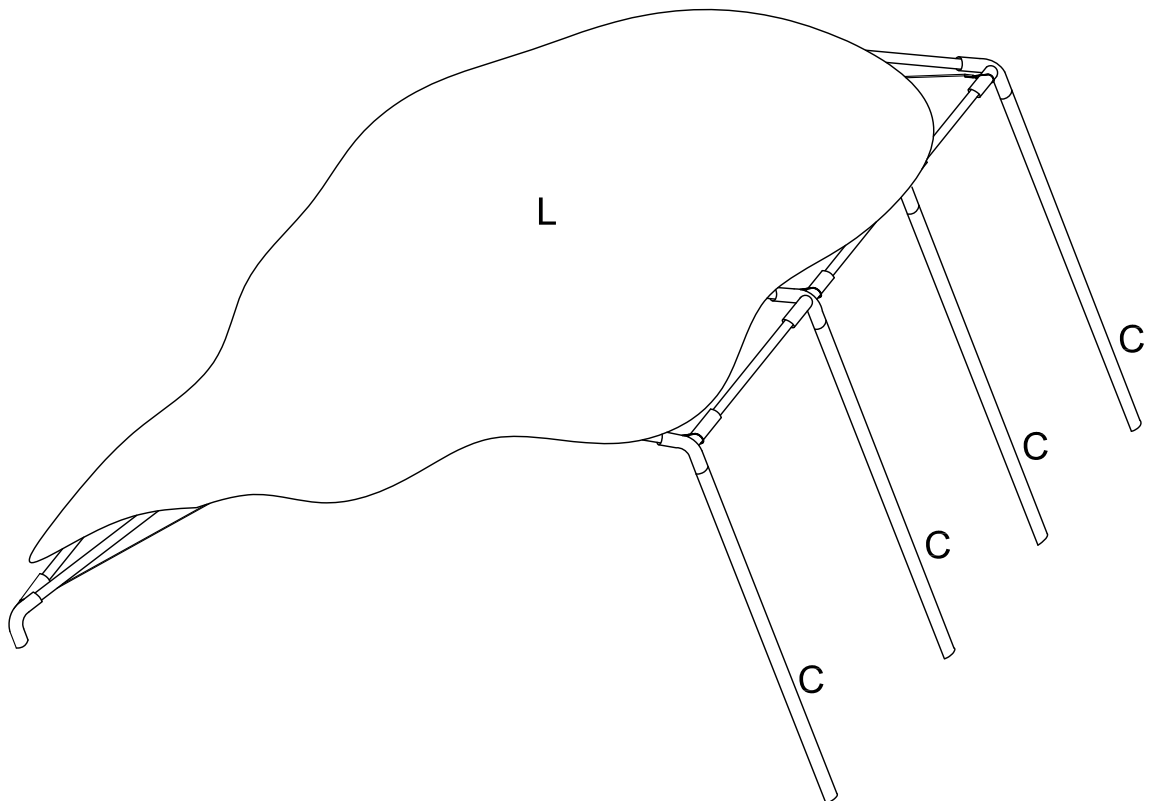


5

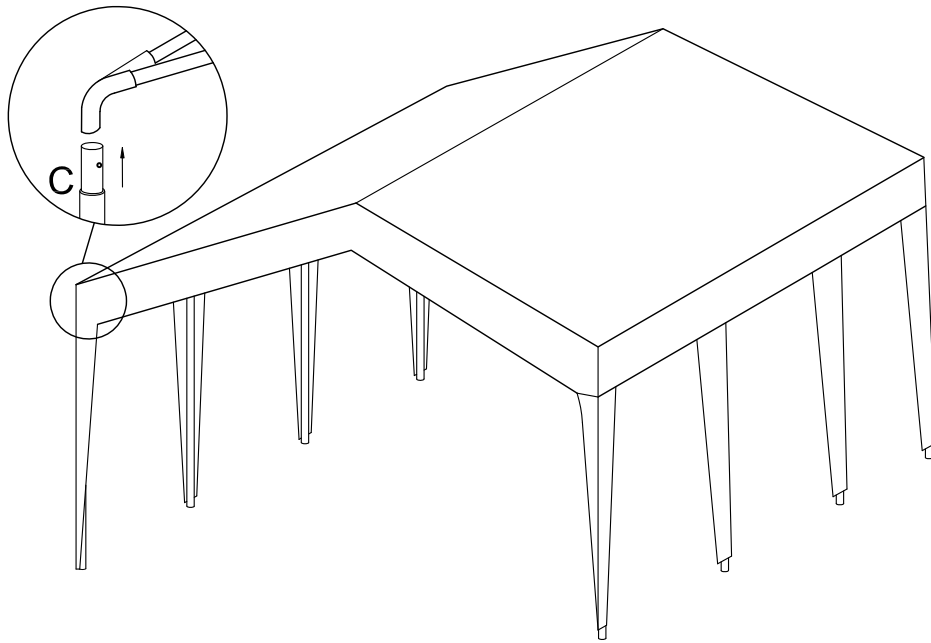

6

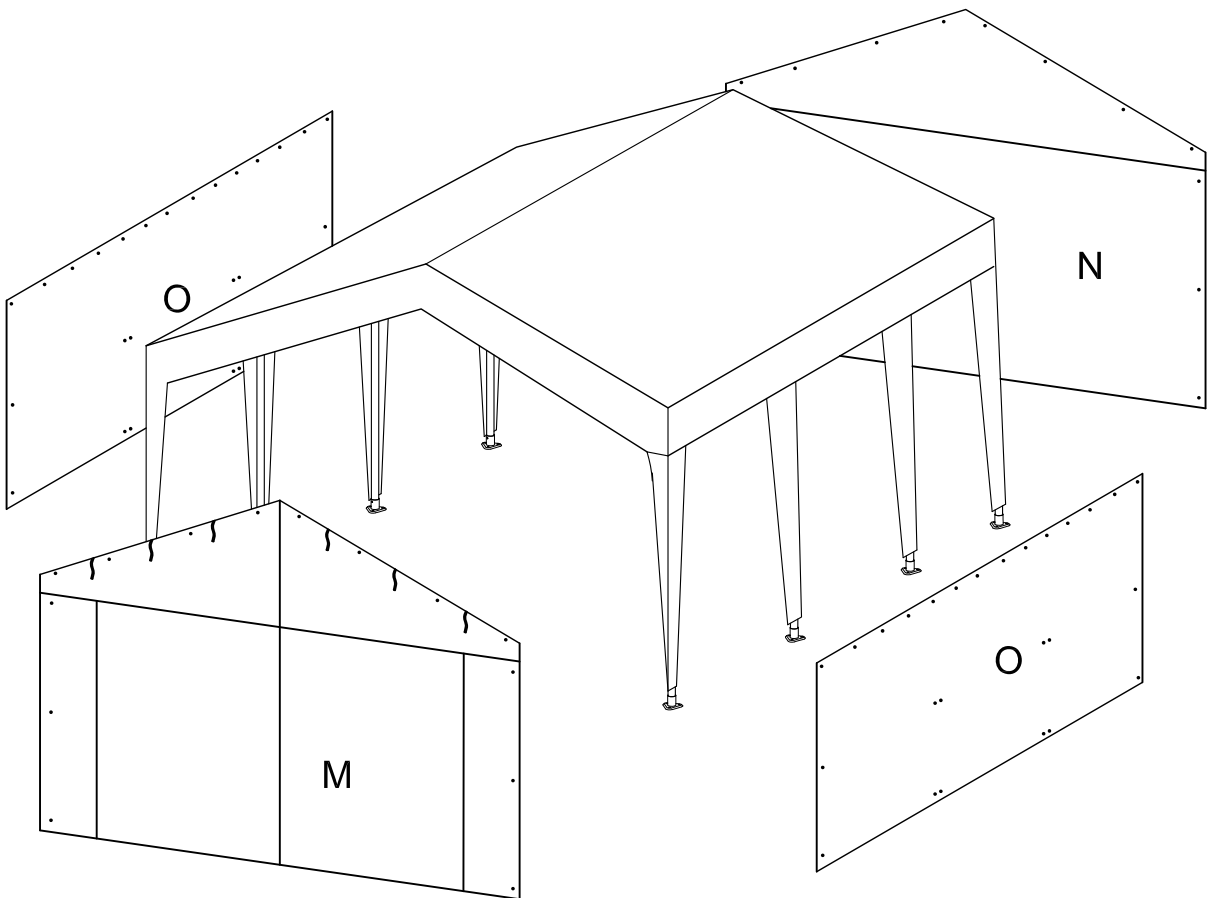

7

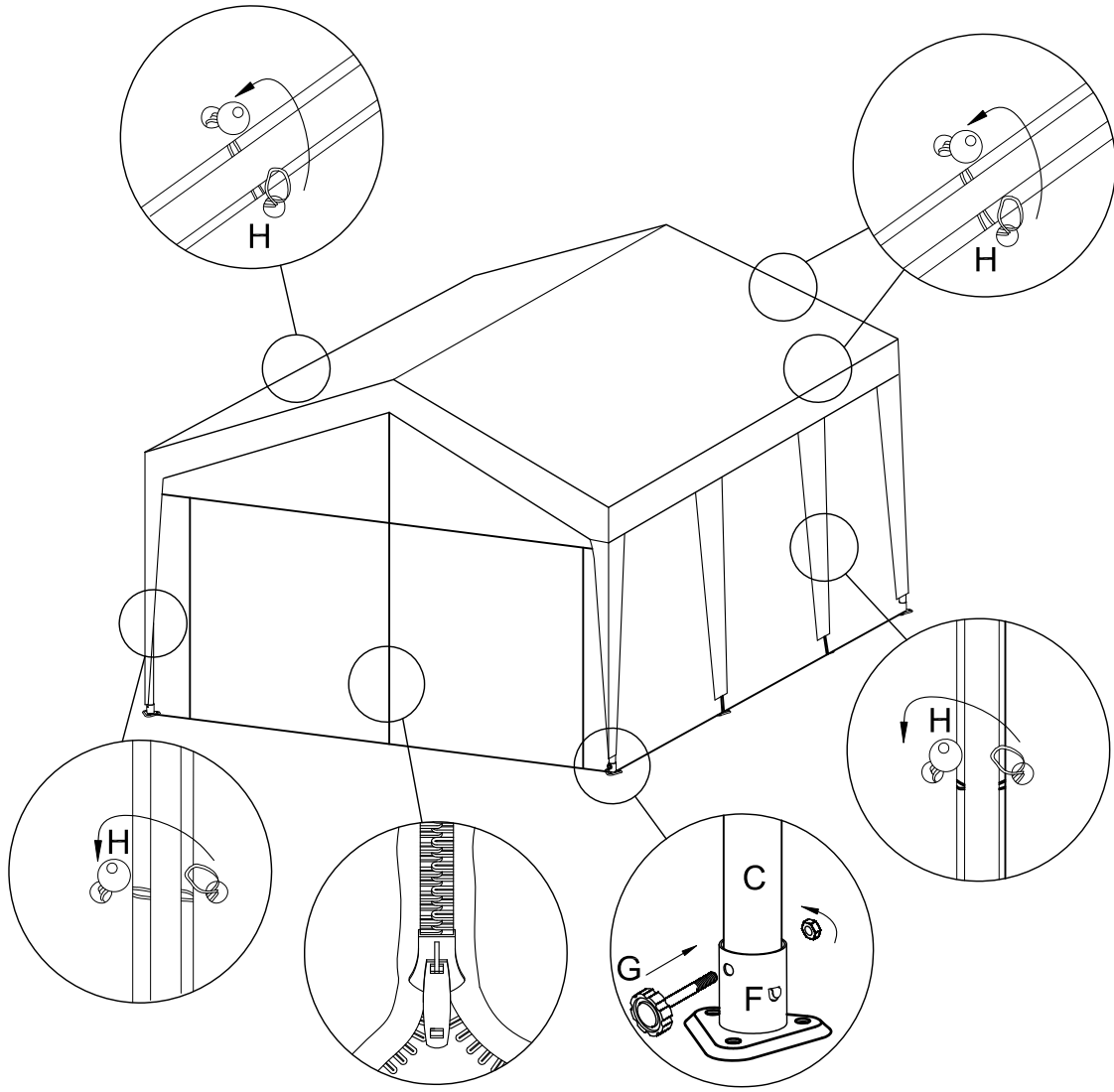

8

