

# SKYFUZE™

## 150 WATT LED BALLOON LIGHT KIT



**5,000K**  
DAYLIGHT COLOR



**19,500**  
LUMEN



**50,000**  
LASTING HOURS



**110-240**  
VOLTS

### SPECIFICATIONS

- Over 11,000 square feet of 360-degree illumination
- 19,500 lumens, <1.5 operating amps, 120-volt input
- Glare-free, diffused lighting
- Lightweight and portable
- Water-resistant LED balloon light rated to IP42 standard
- LED balloon light diffuser material made of heat-resistant and UV-protected nylon
- Integrated fan automatically inflates balloon and cools LED panels
- Engineered with 130 lumen-per-watt Samsung LED chips
- Quick and easy setup on tripod or optional mounting fixtures
- UL approved, RoHS, FCC, CE rating
- Includes heavy-duty telescoping tripod with carry bag
- Dimmable wireless remote
- Hanging 2" C-clamp, eye bolt, and tripod adapters included
- 15 ft spec-grade power cord
- 3-year warranty



ENERGY  
EFFICIENT



DIMMABLE  
REMOTE



ENCLOSED  
FIXTURE



WATER  
RESISTANT



AUTO  
INFLATE



FAST  
INSTALL



SHOCK  
RESISTANT




GLARE  
FREE



## LIGHT COVERAGE

Tripod at 6.5FT Setting

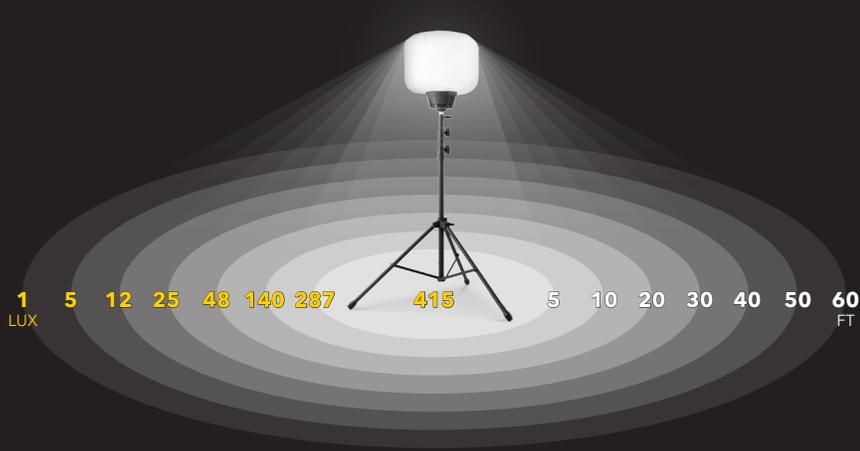

- 150-watt LED Balloon Light
- Luminous Flux: 19,500 lm
- Color Temperature: 5,000k
- Lamp Life: 50,000 hours
- Voltage: 110-240 V AC
- Frequency: 50/60 Hz
- Operating Amperage: 1.5 A
- Power Consumption: 155W
- IP Rating: IP42
- Weight: 6 lb (fixture), 7.1 lb (tripod)

## PARTS INCLUDED



REMOTE CONTROL



TRIPOD ADAPTER



EYE BOLT



2" C-CLAMP

