

SKYFUZE™

60 WATT LED BALLOON LIGHT KIT



5,000K
DAYLIGHT COLOR



7,800
LUMEN



50,000
LASTING HOURS



110-240
VOLTS

SPECIFICATIONS

- Over 5,000 square feet of 360-degree illumination
- 7,800 lumens, <1.0 operating amps, 120-volt input
- Glare-free, diffused lighting
- Lightweight and portable
- Water-resistant LED balloon light rated to IP42 standard
- LED balloon light diffuser material made of heat-resistant and UV-protected nylon
- Integrated fan automatically inflates balloon and cools LED panels
- Engineered with 130 lumen-per-watt Samsung LED chips
- Quick and easy setup on tripod or optional mounting fixtures
- UL approved, RoHS, FCC, CE rating
- Includes heavy-duty telescoping tripod with carry bag
- Dimmable wireless remote
- Hanging 2" C-clamp, eye bolt, and tripod adapters included
- 15 ft spec-grade power cord
- 3-year warranty



ENERGY
EFFICIENT



DIMMABLE
REMOTE



ENCLOSED
FIXTURE



WATER
RESISTANT



AUTO
INFLATE



FAST
INSTALL



SHOCK
RESISTANT




GLARE
FREE



LIGHT COVERAGE

Tripod at 6.5FT Setting

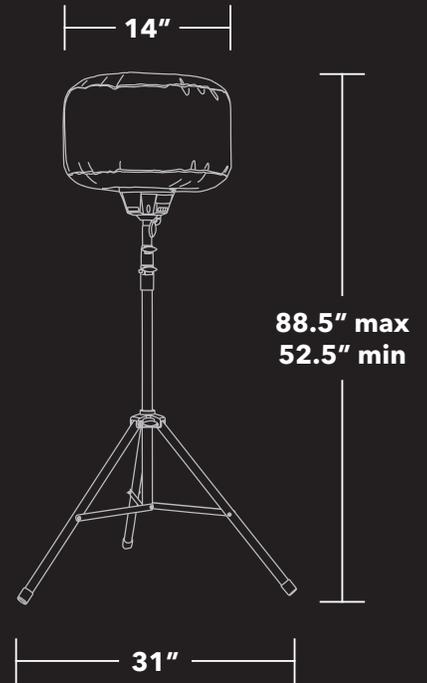

- 60-watt LED Balloon Light
- Luminous Flux: 7,800 lm
- Color Temperature: 5,000k
- Lamp Life: 50,000 hours
- Voltage: 110-240 V AC
- Frequency: 50/60 Hz
- Operating Amperage: 0.5 A
- Power Consumption: 65W
- IP Rating: IP42
- Weight: 6 lb (fixture), 7.1 lb (tripod)

PARTS INCLUDED



REMOTE CONTROL



TRIPOD ADAPTER



EYE BOLT



2" C-CLAMP

