

FIRE RATED ULTRA SLIM REGRESSED LED DOWNLIGHTS



SECOND EDITION


JESCO
LIGHTING GROUP

4" FIRE RATED ULTRA-SLIM REGRESSED DOWNLIGHT



RLF-4612

4" FIRE RATED ULTRA-SLIM REGRESSED LED DOWNLIGHT

LED	90+ CRI	3 SDCM	120V 277V	12W	900 Lm	DIM
110°	IC RATED	AIR TIGHT	FIRE RATED	WET	ETL US	JA8 TITLE 24

Input	120V AC	120V-277V AC
Dimming	TRIAC	0-10V
Power	12W	
CCT	2700K/3000K/3500K/4000K/5000K - Switchable	
Dimensions	5" Ø x 1 1/2" H	
Cut-Out	4 1/4" Ø	
Fire Rated	Code compliant for use in fire-rated constructions up to a maximum of 2-hours	
Environment	Indoor - Wet	

JESCO introduces its newest Fire Rated Downlights. Fixtures are code compliant for use in fire-rated constructions up to a maximum of 2-hours.

Offered in two sizes, 4" and 6" diameters, these downlights feature a very slim regressed profile, measuring just 1.5" in height, and are both IC and Airtight rated, perfect for installation in tight plenums. A traditional bulky housing is not required for Remodel applications. For New Construction, a Universal Mounting Plate with Hanger Bars may be used, sold separately. Fixtures are equipped with a plug-and-play driver housed in a junction box.

Fixtures include a field-selectable Color Temperature options of 2700K, 3000K, 3500K, 4000K and a cooler 5000K. High 90+CRI 3-step MacAdam Ellipse single binning LEDs provide excellent color rendition with exceptional color consistency. Dimmable with TRIAC or 0-10V.


Fire Rated Downlights are California JA8 Title 24 compliant.



RLF-4612FR model with CCT Selectable Switch on Junction Box



RLF-4612FR-UNI model with 5-way Inline CCT Selectable Switch

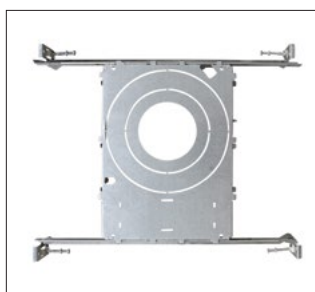

RLH-346-NC-UNI

Universal Mounting Plate with Hanger Bars

For sizes: 4 1/4" or 6 1/4"

The Mounting Plate has a dedicated location for the Driver/Junction Box. (Optional, order separately)



EM-LIN

15W Remote Mounted Emergency Battery

- Universal input 100-347V AC
- Battery protection for over-temperature, overcharge, over-discharge, shortcircuit,
- Works with AC/DC sensor
- Includes: Charging Indicator / Test Switch, Handheld Remote Tester

TO ORDER

SERIES	SIZE/WATT	RATINGS	CCT	TRIM	OPTION
RLF	- 4612		- SW5	- WH	-
	4612 - 4" 12W	FR - Fire Rated 120V FR-UNI - Fire Rated, 120-277V	SW5 - Switchable (27/30/35/40/50K)	WH - White Trim	EM - Emergency Battery¹

¹ Emergency battery pack is only available with 0-10V dimming driver. 0-10V control not required. Product specifications subject to change without notice.

6" FIRE RATED ULTRA-SLIM REGRESSED DOWNLIGHT



RLF-6615

6" FIRE RATED ULTRA-SLIM REGRESSED LED DOWNLIGHT

LED	90+ CRI	3 SDCM	120V 277V	15W	1100 Lm	DIM
110°	IC RATED	AIR TIGHT	FIRE RATED	WET	ETL US	JA8 TITLE 24


Input	120V AC	120V-277V AC
Dimming	TRIAC	0-10V
Power	15W	
CCT	2700K/3000K/3500K/4000K/5000K - Switchable	
Dimensions	7" Ø x 1 1/2" H	
Cut-Out	6 1/4" Ø	
Fire Rated	Code compliant for use in fire-rated constructions up to a maximum of 2-hours	
Environment	Indoor - Wet	



RLF-6615FR model with CCT Selectable Switch on Junction Box



RLF-6615FR-UNI model with 5-way Inline CCT Selectable Switch

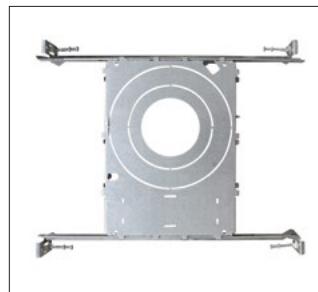

RLH-346-NC-UNI

Universal Mounting Plate with Hanger Bars

For sizes: 4 1/4" or 6 1/4"

The Mounting Plate has a dedicated location for the Driver/Junction Box. (Optional, order separately)



EM-LIN


15W Remote Mounted Emergency Battery

- Universal input 100-347V AC
- Battery protection for over-temperature, overcharge, over-discharge, shortcircuit,
- Works with AC/DC sensor
- Includes: Charging Indicator / Test Switch, Handheld Remote Tester

TO ORDER

SERIES	SIZE/WATT	RATINGS	CCT	TRIM	OPTION
RLF	- 6615		- SW5	- WH	-
	6615 - 6" 15W	FR - Fire Rated 120V FR-UNI - Fire Rated, 120-277V	SW5 - Switchable (27/30/35/40/50K)	WH - White Trim	EM - Emergency Battery ¹

¹Emergency battery pack is only available with 0-10V dimming driver. 0-10V control not required. Product specifications subject to change without notice.

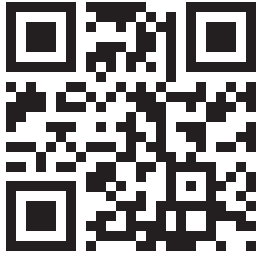

For more details and product specifications please visit JESCOLIGHTING.COM



**NEW YORK
CORPORATE OFFICE**
15 Harbor Park Drive
Port Washington NY 11050
TEL 800 527 7796
FAX 855 265 5768

LOS ANGELES
219 South 6th Avenue
City of Industry CA 91746
TEL 626 333 3661
TEL 855 654 0110

JESCOLIGHTING.COM
info@jescolighting.com

© 2023 JESCO Lighting
LCAT-FIRE-RATED-DL-V2-2023

