


ADVANTAGE COLLECTION MODEL NO. 1206BLK EXECUTIVE MID BACK CHAIR W/BLACK FRAME




CHAIR FUNCTIONS

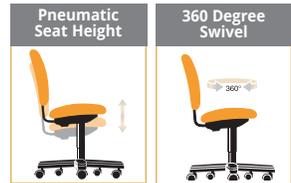

Adjusts "up and down" seat height relative to the floor.

Allows seat "Rotation" in a full circle.

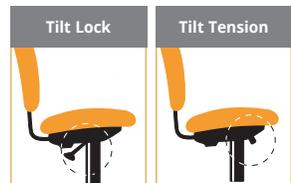

"Locks seat and back" in an upright position.

Allows user to adjust "resistance" with which chair reclines or tilts.

DESCRIPTION

- Swivel tilt, tilt lock, & tilt tension controls
- 27" Nylon base w/hooded double wheel casters
- Pneumatic gas lift height adjustment
- Stylish & contemporary
- UPS-able
- Ready-to-assemble
- Non-toxic / ANSI/BIFMA
- Environmentally friendly
- Fire-resistant
- Weight Capacity (LBS): 275
- Product Weight (LBS): 33.74

DIMENSIONS

Overall: 24"W x 26¼"D x 37¼"-40¾"H
 Seat: 19¾"W x 18¼"D x 18½"-22"H
 Seat to Back Height: 37½"- 40¾"
 Seat Back Width: 19¾"
 Seat Back Depth: 3¾"
 Seat Back Height: 22¹⁰⁄₁₆"
 Floor to Seat: 18½"-22¹⁰⁄₁₆"
 Cushion Width: 19¾"
 Cushion Depth: 18½"
 Cushion Thickness: 3¾"
 Cushion Fill Material: Foam
 Foam Density in Pounds (Per Cubic Foot): 25

CHAIR ARM/BASE

Arm Width: 2¾"
 Arm Depth: 16¹⁵⁄₁₆"
 Arm Height (Top to Bottom): 9¹³⁄₁₆"
 Floor to Arm: 25½"-28¹³⁄₁₆"
 Caster Usage: Dual Wheel

MATERIAL ATTRIBUTES

Leather-Soft Vinyl™
 Plastic Frame & Base
 Plastic Casters

SHIPPING DETAILS

Carton Length: 24.40"
 Carton Depth: 12.20"
 Carton Height: 23"
 Carton Weight (LBS): 33.74

UPHOLSTERY IN STOCK



BLK Black
 Leather-Soft Vinyl™
 (NOR-CAREPLUSBLK)

Last Updated: 01/2020



Ready to Assemble



Environmentally Friendly

Warranty: Limited Lifetime

OFFICESOURCE.COM