


PYROSB *Wall Mounting Metal Bracket*

FEATURES & BENEFITS

- Rust free metal bracket.
- Adjustable length for optimizing the distance from the wall.
- Color—Silver.
- Pre Drilled holes for easy mounting.
- Holes along the arm for wire ties to secure the PYROSENSE cable/ conduit.
- Designated opening for wall through wiring.

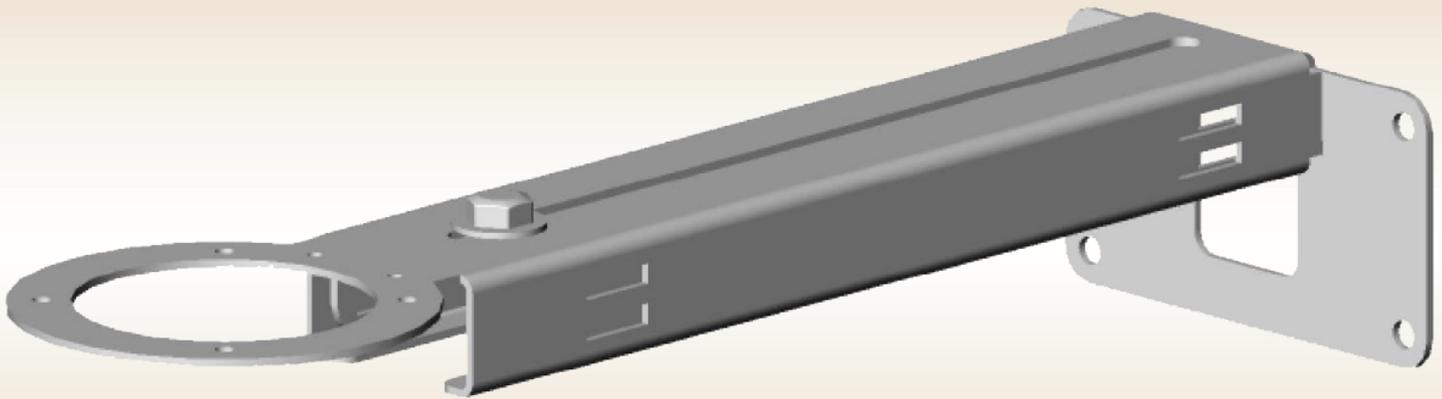

DESCRIPTION

The PYROSB is a metal arm with adjustable length (375-600 mm / 14.7-23.6 inch) for the PYROSENSE snow sensor of the PYRO-X system. The PYROSENSE fits precisely to the round surface and the holes are located on the metal ring secure the snow sensor assembly. Adjusting the arm length is easy and done using the top screw. The rectangular holes along the arm provide easy holding point for wire ties, securing the cable of the PYROSENSE. An opening in the wall plate provides a direct access to feed the wire into the house.

TECHNICAL SPECIFICATIONS

Length	14.7—23.6 inches (375-600mm)	Storage & Operating temp.	-50° F to 220° F (-40°C to 105C)
Material	Metal	Installation	Wall mounted with 4 screws

Part #	Item	UPC# 093319	Description
PYROSB	Mounting Bracket	42326	Wall mounted, adjustable metal fixture

The performance specifications are nominal and conform to acceptable industry standards. For applications at conditions beyond these specifications, consult King Electrical Mfg. Co. King shall not be liable for damages resulting from misapplication or misuse of its products. This document is subject to change without any notice.