


Regular Helical Spring Lock Washers

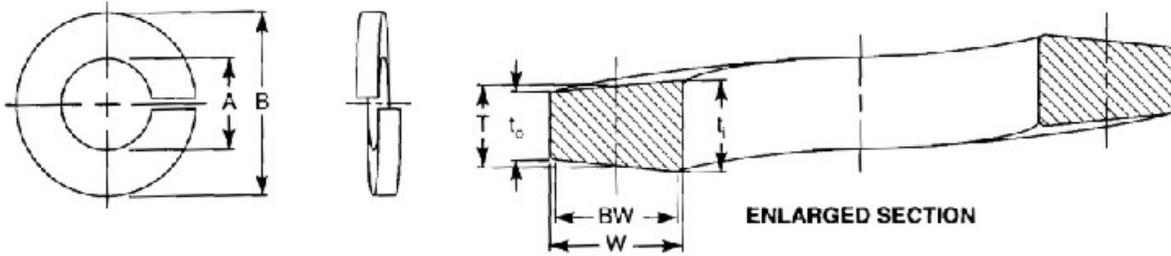

DIMENSIONAL DATA		
Type: Regular Helical Spring Lock Washers	Standard: ASME B18.21.1-2009	Size: 1/4
Nominal: 0.25	A - Inside Diameter: 0.260 - 0.252	B - Outside Diameter: 0.487 Max
T (Ref.) - Mean Section Thickness $(t_1 + t_0)/2$: 0.062 Min	W - Section Width: 0.109 Min	BW - Bearing Width: 0.076 Min
MATERIAL DATA		
Typical Material: Silicon-Bronze (UNS C65100 or C65500)	Hardness: HRB 90 min.	
FINISH DATA		
Finish Type: Plain	K factor (ref. DIN 946): 0.2	RoHS/REACH Compliant: yes
Color: colorless		

