
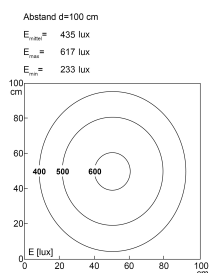


Recessed luminaire TUBELED_40 II Integrated, 395 mm x 74 mm x 3 mm (15,55" x 2,91" x 0,12")

LED recessed luminaire

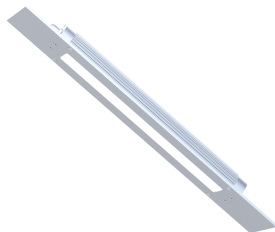

Product-Nr.	151110-03
EAN:	4260556626239
Model:	TUBELED_40 II Integrated
Order number:	151110-03
Model:	TUBELED_40 II Integrated
Type:	LED recessed luminaire
Illuminant:	SMD LED
Power consumption:	~12 W
Lamp luminous flux:	1899 lm
Lamp luminous efficiency:	~155 lm/W
Light distribution:	Light Forming Technology
Light colour:	daylight white (5200 - 5700K)
Connected load:	24V DC $\pm$ 10%
Connection (connector):	M12 A-coded
Degree of protection:	IP67/IP69K
Class of protection:	III
Glare control:	diffused safety glass
Beam angle (optics):	100°
Operating temperature:	-30 °C -> +60 °C (-22 °F -> 140 °F)
Colour rendering (Ra):	>85
Lamps lifetime:	> 100.000h (L80/B10)
Housing material:	aluminium
Cover material:	safety glass, 4 mm (0,16")
Height [B] x Width [C]:	32 mm x 74 mm (~1.26" x ~2.91"), aperture 3 mm (~0.12") built-up
Length [A]:	395 mm (~15,55")
Weight (net):	700 g (~25 oz)
Gross weight:	950 g (~34 oz)
Risk group (DIN EN 62471):	free group
Markings:	CE, UKCA, ETL Listed (5003529), D mark
Dimmable:	optional via accessories
Made in:	Germany