


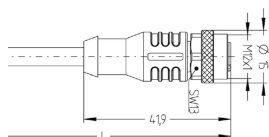

Sensor cable, PUR, black

1	BN	1
2	WH	2
3	BU	3
4	BK	4



Product-Nr.	200100-03
EAN:	4260556621883
Model:	Sensor Kabel, M12 Buchsen 4-Polig
Order number:	200100-03
Model:	Sensor Kabel, M12 Buchsen 4-Polig
Type:	Sensor cable, PUR, black
Coding:	A-coded
Amount:	1 piece
Suitable for:	LED2WORK lights 24V DC, except for RGB and RGB-W
Cable length:	10 m (~32,81 ft.)
Attachment to a luminaire:	Connector socket M12, straight
Cable ends:	M12 plug, straight / M12 socket, straight
Number of poles:	4
Material:	Contact carrier: plastic, TPU, BK; Coupling: metal, CuZn, nickel-plated; Seal: FPM / FKM; Contacts: metal, CuSn, gold-plated
Nominal voltage:	250V
Current load per PIN:	4000 mA
Ambient temperature:	-30°C -> +90 °C (-22 °F -> 194 °F)
Passage resistance (ohms):	< 0,005
Insulation resistance (Ohm):	>= 100 Mio.
RoHS Directive:	Yes
UL:	Yes
Protection class (mounting):	IP65, IP67, IP68
Cable material:	PUR
Handle body material:	Plastic, TPU, BK
Contact carrier material:	Plastic, TPU, BK
Cover material:	Metal, CuZn, nickel-plated
Sealing material:	FPM / FKM
Contact material:	Metal, CuSn, gold-plated
Standards:	IEC 61076-2-101
Weight (net):	300 g (~11 oz)
Gross weight:	350 g (~12 oz)