




Sensor cable, PUR, black

1	BN
2	WH
3	BU
4	BK
5	GN YE

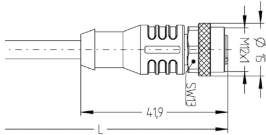

Product-Nr.	200100-10
EAN:	4260556623368
Model:	Sensor Kabel, offen/M12 Buchse 5-Polig
Order number:	200100-10
Model:	Sensor Kabel, offen/M12 Buchse 5-Polig
Type:	Sensor cable, PUR, black
Coding:	A-coded
Amount:	1 piece
Suitable for:	LED2WORK lights 24V DC, including for RGB and RGB-W luminaires
Cable length:	5 m (~16,4 ft.)
Attachment to a luminaire:	Connector socket M12, straight
Cable ends:	open ends, 5 wires / M12 socket, straight
Number of poles:	5
Material:	Contact carrier: plastic, TPU, BK; Coupling: metal, CuZn, nickel-plated; Seal: FPM / FKM; Contacts: metal, CuSn, gold-plated
Nominal voltage:	250V
Current load per PIN:	4000 mA
Ambient temperature:	-30°C -> +90 °C (-22 °F -> 194 °F)
Passage resistance (ohms):	< 0,005
Insulation resistance (Ohm):	>= 100 Mio.
RoHS Directive:	Yes
UL:	Yes
Protection class (mounting):	IP65, IP67, IP68
Cable material:	PUR
Handle body material:	Plastic, TPU, BK
Contact carrier material:	Plastic, TPU, BK
Cover material:	Metal, CuZn, nickel-plated
Sealing material:	FPM / FKM
Contact material:	Metal, CuSn, gold-plated
Standards:	IEC 61076-2-101
Weight (net):	150 g (~5 oz)
Gross weight:	200 g (~7 oz)