


Surface-mounted device with attachment via an elongated hole

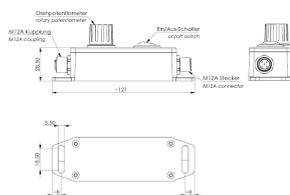

Product-Nr.	210700-04
EAN:	4260556622163
Model:	LED2WORK DIMMbox
Order number:	210700-04
Model:	LED2WORK DIMMbox
Type:	Surface-mounted device with attachment via an elongated hole
Power:	max. 144 W
Through voltage :	24V DC
Current load max.:	6000 mA
Assignment of PIN 1 input / output:	24V DC / -
Assignment of PIN 2 input / output:	- / -
Assignment of PIN 3 input / output:	GND / DIM-
Assignment of PIN 4 input / output:	24V DC / DIM+
Material:	Casing: ABS
Dimming:	using a rotary potentiometer
INPUT/OUTPUT:	M12 socket / M12 plug A-type coded
Voltage range:	24V DC
Power supply:	external
Degree of protection:	IP54
Class of protection:	III
Operating temperature:	-20 °C -> +50 °C (-4 °F -> 122 °F)
Housing material:	plastic
Dimensions (mm):	122 mm x 38 mm x 45 mm (~4,8" x ~1,5" x ~1,77")
Weight (net):	100 g (~4 oz)
Gross weight:	150 g (~5 oz)
Feature:	Universal DIMMbox for all LED2WORK 24V DC luminaires, except for RGB