

Project:

Type:

Prepared By:

Date:



UPC: 019813750101



### Features and Benefits

- Energy efficient replacement for incandescent and halogen reflector lamps
- Constructed from durable plastic which lowers risk of breakage
- Rated for use in enclosed and open fixtures in dry or damp locations
- Frosted lens produces smooth diffuse light
- Longer lifespan compared to legacy equivalents minimizes replacement and maintenance costs
- ENERGY STAR Compliant
- Dimmable with common dimmer types (see Dimmer Compatibility List)

## Technical Specifications

### Performance

**Product Type:**

Reflector

**Input Wattage:**

11W

**Wattage Equivalency:**

65W Incandescent

**Lumens (Nominal):**

900lm

**Efficacy:**

82 lm/W

**L70 Lifespan:**

25,000 Hours

### Construction

**Bulb Shape:**

BR40

**Base Type:**

E26

**For Use Outdoors in Open Fixtures:**

No

### LED Characteristics

**Color Temperature:**

3000K Warm White

**Color Accuracy (CRI):**

90 CRI

### Electrical

**Power Factor:**

0.9

**Operating Temperature:**

-20°C - 45°C (-4°F - 113°F)

**Dimmable:**

Yes, down to 10%

**Input Voltage:**

120V

**Input Current @ 120V:**

92mA

**Operating Frequency:**

60 Hz

## Technical Specifications (continued)

### Electrical

#### Flicker:

<30%

### Optical

#### Beam Angle:

110°

### Other

#### Warranty:

RAB warrants that our LED products will be free from defects in materials and workmanship for a period of three (3) years from the date of delivery to the end user, including coverage of light output, color stability, driver performance and fixture finish. RAB's warranty is subject to all terms and conditions found at [rablighting.com/warranty](http://rablighting.com/warranty).

### Compliance

#### UL Listed:

Yes

#### ENERGY STAR V2.0:

This product is ENERGY STAR® Version 2.0 Certified

#### Energy Star ID:

2330060


### California Energy Commission (CEC) Status:

Lawful for sales in California

## Case and Pallet Dimensions

	QTY	LENGTH (in)	WIDTH (in)	HEIGHT (in)
CASE	6	15.7	10.6	7.2
PALLET	360	47.1	36.9	50.7

## Dimension

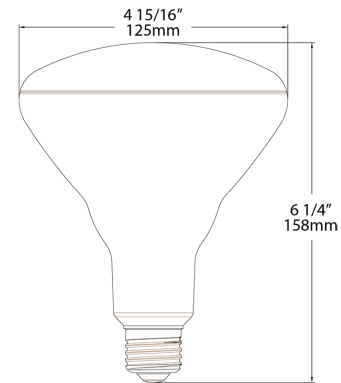

Light Distribution

