




**PRODUCT DESCRIPTION**

A transitional look that works in a broad range of interiors featuring metal frames finished in either Oiled Rubbed Bronze for the traditional home or Satin Nickel for a more contemporary look. Simple Frost glass shades compliment the overall design.

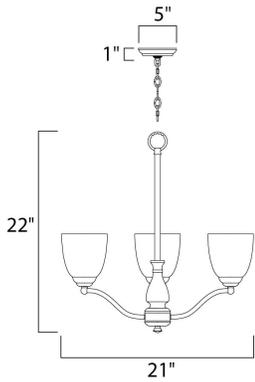

**MEASUREMENTS**

DIMENSION : 21" L x 21" W x 22" H  
 CANOPY : 4.75" W x 1" H x 4.75" L  
 HANGING WEIGHT : 6.8 lb

**LAMPING**

INPUT VOLTAGE : 120V  
 BULB : 3 x 60W Incandescent E26 Medium , 180W Total  
 BULB INCLUDED : (Not Included)  
 DIMMABLE : Yes

**FINISHES OPTION**

-  Black
-  Oil Rubbed Bronze
-  Satin Nickel

**GLASS**

Frosted FT

**MATERIAL**

Steel, Glass

**RATINGS**

cULus  
 Dry Location



**ADDITIONAL**

ADJUSTABLE  
 OPERATING TEMPERATURE:  
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)  
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER  
 101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com