




**PRODUCT DESCRIPTION**

Minimalistic frames in a variety of brilliant finishes with your choice of either frosted or clear glass shades. While its sleek simplicity are modern in design, the Corona perfectly shines in any indoor application or style.

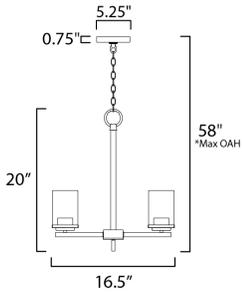

\*max overall height

**MEASUREMENTS**

- DIMENSION : 16.5" L x 16.5" W x 20" H
- MAX OAH : 58" OAH
- CANOPY : 5.25" W x 0.75" H x 5.25" L
- HANGING WEIGHT : 6.24 lb

**LAMPING**

- INPUT VOLTAGE : 120V
- BULB : 3 x 60W Incandescent E26 Medium , 180W Total
- BULB INCLUDED : (Not Included)
- DIMMABLE :

**FINISHES OPTION**

-  Black
-  Satin Brass
-  Satin Nickel

**GLASS**

Clear CL

**MATERIAL**

Steel + Glass

**RATINGS**

cETLus  
Dry Location



**ADDITIONAL**

ADJUSTABLE  
OPERATING TEMPERATURE:  
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)  
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER  
101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com