



PRODUCT DESCRIPTION

Minimalistic frames in a variety of brilliant finishes with your choice of either frosted or clear glass shades. While its sleek simplicity are modern in design, the Corona perfectly shines in any indoor application or style.

FINISHES OPTION

-  Black
-  Satin Brass
-  Satin Nickel

GLASS

Clear CL

MATERIAL

Steel + Glass


RATINGS

cETLus
Dry Location



ADDITIONAL

ADJUSTABLE
OPERATING TEMPERATURE:
-20°C (-4°F), 40°C (104°F)

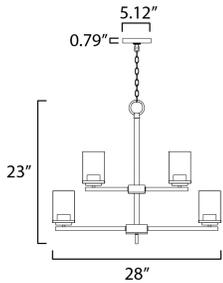

MEASUREMENTS

DIMENSION : 28" L x 28" W x 25" H
 MAX OAH : 99" OAH
 CANOPY : 5.25" W x 0.75" H x 5.25" L
 HANGING WEIGHT : 13.27 lb

LAMPING

INPUT VOLTAGE : 120V
 BULB : 9 x 60W Incandescent E26 Medium , 540W Total
 BULB INCLUDED : (Not Included)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER
 101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com