




PRODUCT DESCRIPTION

Minimalistic frames in a variety of brilliant finishes with your choice of either frosted or clear glass shades. While its sleek simplicity are modern in design, the Corona perfectly shines in any indoor application or style.

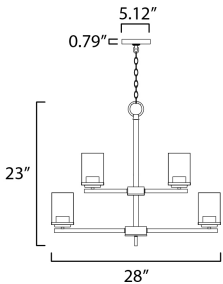

MEASUREMENTS

DIMENSION : 28" L x 28" W x 25" H  
MAX OAH : 99" OAH  
CANOPY : 5.25" W x 0.75" H x 5.25" L  
HANGING WEIGHT : 13.27 lb

LAMPING

INPUT VOLTAGE : 120V  
BULB : 9 x 60W Incandescent E26 Medium , 540W Total  
BULB INCLUDED : (Not Included)

FINISHES OPTION

- Black
- Satin Brass
- Satin Nickel

GLASS

Clear CL

MATERIAL

Steel + Glass

RATINGS

cETLus  
Dry Location



ADDITIONAL

ADJUSTABLE  
OPERATING TEMPERATURE:  
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)  
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746  
EASTERN DISTRIBUTION CENTER  
101 GARDNER PARK | PEACHTREE CITY, GA 30269  
P. 626.956.4200 | F. 626.956.4225 | maximlighting.com