




**PRODUCT DESCRIPTION**

Minimalistic frames in a variety of brilliant finishes with your choice of either frosted or clear glass shades. While its sleek simplicity are modern in design, the Corona perfectly shines in any indoor application or style.

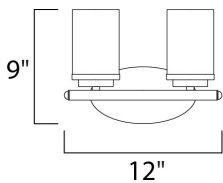


**MEASUREMENTS**

DIMENSION : 12" W x 9" H x 6" Ext  
 BACK PLATE : 6.75" HCO  
 CANOPY : 4.5" W x 0.79" H x 8.25" L  
 HANGING WEIGHT : 2.1 lb

**LAMPING**

INPUT VOLTAGE : 120V  
 BULB : 2 x 60W Incandescent E26 Medium , 120W Total  
 BULB INCLUDED : (Not Included)  
 LIGHTING\_DIRECTION : Omni

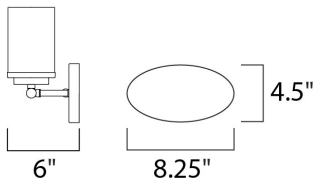

**FINISHES OPTION**

-  Black
-  Oil Rubbed Bronze
-  Polished Chrome
-  Satin Brass
-  Satin Nickel

**GLASS**

Clear CL

**MATERIAL**

Steel + Glass

**RATINGS**

cETLus  
 Damp Location



**ADDITIONAL**

INSTALL UP/DOWN: Up/Down  
 OPERATING TEMPERATURE:  
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)  
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER  
 101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com