



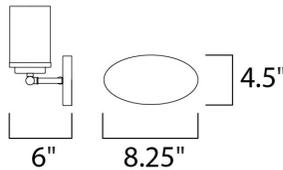

PRODUCT DESCRIPTION

Minimalistic frames in a variety of brilliant finishes with your choice of either frosted or clear glass shades. While its sleek simplicity are modern in design, the Corona perfectly shines in any indoor application or style.

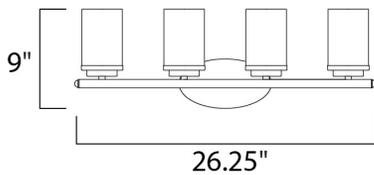

MEASUREMENTS

DIMENSION : 26.25" W x 9" H x 6" Ext
 BACK PLATE : 6.75" HCO
 CANOPY : 4.5" W x 0.79" H x 8.25" L
 HANGING WEIGHT : 3.61 lb

LAMPING

INPUT VOLTAGE : 120V
 BULB : 4 x 60W Incandescent E26 Medium , 240W Total
 BULB INCLUDED : (Not Included)
 DIMMABLE :
 LIGHTING_DIRECTION : Omni

FINISHES OPTION

-  Black
-  Oil Rubbed Bronze
-  Polished Chrome
-  Satin Brass
-  Satin Nickel

GLASS

Clear CL

MATERIAL

Steel + Glass

RATINGS

cETLus
 Damp Location



ADDITIONAL

INSTALL UP/DOWN: Up/Down
 OPERATING TEMPERATURE:
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER
 101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com