




PRODUCT DESCRIPTION

Drum shades in a variety of fabrics and materials are a core lighting offering. Flush mounts, pendants, and ADA sconces are available in options of linen, organza, grasscloth, and sound absorbing grey felt shades. An internal acrylic diffuser, illuminated by an evenly dispersed powerful LED light source, directs light downward and produces an ambient glow inside the outer shade. This lens features a crisp and tidy twist-lock mechanism that eliminates any visible hardware. whether it is put in a residential or commercial context, this collection meets the necessary application needs while adding style to the space.

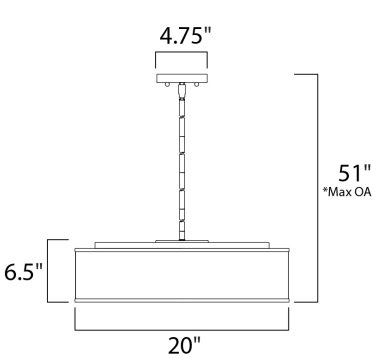

*max overall height

MEASUREMENTS

DIMENSION	: 20" L x 20" W x 8.88" H
MAX OAH	: 53.38" OAH
CANOPY	: 17.75" W x 1.25" H x 17.75" L
HANGING WEIGHT	: 9.01 lb

LAMPING

INPUT VOLTAGE	: 120V
LUMENS	: 2,270 Rated (2,000 Del.)
BULB	: 5 x 6.5W LED AC Integrated , 32W Total
BULB INCLUDED	: (Integrated)
DIMMABLE	: Triac or ELV
CRI	: 90 CRI
COLOR_TEMP	: 3000K

FINISHES OPTION

	Oil Rubbed Bronze
	Satin Nickel

MATERIAL

Steel, Acrylic, Fabric

RATINGS

cETLus
 Dry Location



ADDITIONAL

RATED LIFE 35000 Hours
 OPERATING TEMPERATURE:
 -20°C (-4°F), 40°C (104°F)

PHOTOMETRIC: Report Found Online

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746
 EASTERN DISTRIBUTION CENTER
 101 GARDNER PARK | PEACHTREE CITY, GA 30269
 P. 626.956.4200 | F. 626.956.4225 | maximlighting.com