



PRODUCT DESCRIPTION


A minimalist design featuring a metal frame of Black round glass balls in your choice of Mirror Smoke for a contemporary style or Champagne for more transitional decors. The value of this collection is increased by the inclusion of LED bulbs.

MEASUREMENTS

DIMENSION : 9.75" L x 9.75" W x 14.5" H
 MAX OAH : 136" OAH
 CANOPY : 4.75" W x 0.75" H x 4.75" L
 HANGING WEIGHT : 4.67 lb


LAMPING

INPUT VOLTAGE : 120V
 LUMENS : 500 Rated (450 Del.)
 BULB : 1 x 4W LED G9 , 4W Total
 BULB INCLUDED : (Included)
 DIMMABLE : Triac CL
 COLOR_TEMP : 3000K

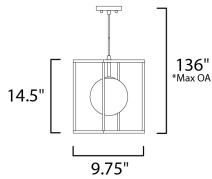

*max overall height

FINISHES OPTION

-  Black / Polished Chrome
-  Black / Satin Brass

GLASS

Champagne CMP

MATERIAL

Steel, Glass

RATINGS

cETLus
 Dry Location



ADDITIONAL

ADJUSTABLE
 SLOPE: 90
 RATED LIFE 15000 Hours
 OPERATING TEMPERATURE:
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER
 101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com