




PRODUCT DESCRIPTION

Cylinders in Clear Seeded glass on simple Satin Nickel frames or matte Black frames with Antiqued Brass socket covers. Pivoting arms on chandelier allow it to direct light up or down. Use filament lamps either tubular or Edison in shape for a Coastal or Industrial look, or use a traditional A19 to create a more transitional look. A full range of affordable lighting for the kitchen, dining room, bathroom, or bedroom that easily complements fashionable finishes and lasting styles.

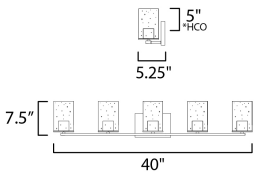

*height from center of outlet to the top of the fixture

MEASUREMENTS

DIMENSION : 40" W x 7.5" H x 5.25" Ext
BACK PLATE : 7" W x 4.75" H x 5" HCO
HANGING WEIGHT : 3.32 lb

LAMPING

INPUT VOLTAGE : 120V
BULB : 5 x 60W Incandescent E26 Medium , 300W Total
BULB INCLUDED : (Not Included)
LIGHTING_DIRECTION : Omni

FINISHES OPTION

- Antique Brass / Black
- Satin Nickel

GLASS

Seedy CD

MATERIAL

Steel + Glass

RATINGS

cETLus
Damp Location



ADDITIONAL

INSTALL UP/DOWN: Up/Down
OPERATING TEMPERATURE:
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746
EASTERN DISTRIBUTION CENTER
101 GARDNER PARK | PEACHTREE CITY, GA 30269
P. 626.956.4200 | F. 626.956.4225 | maximlighting.com