





PRODUCT DESCRIPTION

Cylinders in Clear Seeded glass on simple Satin Nickel frames or matte Black frames with Antiqued Brass socket covers. Pivoting arms on chandelier allow it to direct light up or down. Use filament lamps either tubular or Edison in shape for a Coastal or Industrial look, or use a traditional A19 to create a more transitional look. A full range of affordable lighting for the kitchen, dining room, bathroom, or bedroom that easily complements fashionable finishes and lasting styles.

FINISHES OPTION

-  Antique Brass / Black
-  Satin Nickel

GLASS

Seedy CD

MATERIAL

Steel + Glass


RATINGS

cETLus
Dry Location



ADDITIONAL

OPERATING TEMPERATURE:
-20°C (-4°F), 40°C (104°F)

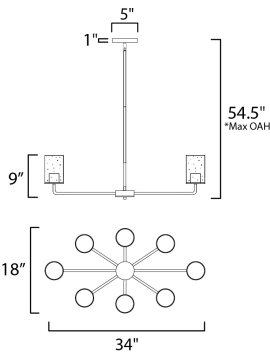

MEASUREMENTS

- DIMENSION : 34" W x 9" H
- MAX OAH : 54.5" OAH
- CANOPY : 5" W x 1" H x 5" L
- HANGING WEIGHT : 14.8 lb

LAMPING

- INPUT VOLTAGE : 120V
- BULB : 8 x 60W Incandescent E26 Medium , 480W Total
- BULB INCLUDED : (Not Included)

*max overall height

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER
101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com