




**PRODUCT DESCRIPTION**

Sweeping metal accents links create classic curves on a minimalist chandelier. Available in hand-rubbed Chestnut Bronze or elegant Gold Leaf finishes. Add crystal accents to elevate the design for a more extravagant glamour. The design manages to evoke French Country charm and enchants any room it illuminates.

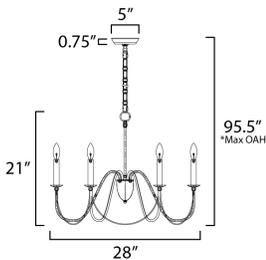

\*max overall height

**MEASUREMENTS**

- DIMENSION : 28" L x 28" W x 22" H
- MAX OAH : 94.5" OAH
- CANOPY : 1.14" H x 5.1" L
- HANGING WEIGHT : 4.3 lb

**LAMPING**

- INPUT VOLTAGE : 120V
- BULB : 6 x 60W Incandescent E12 Candelabra , 360W Total
- BULB INCLUDED : (Not Included)
- DIMMABLE : Y
- LIGHTING\_DIRECTION : Up

**FINISHES OPTION**

- Chestnut Bronze
- Gold Leaf

**GLASS**

Crystal CRY

**MATERIAL**

Iron & Crystal

**RATINGS**

cULus  
Dry Location



**ADDITIONAL**

INSTALL UP/DOWN: Up  
OPERATING TEMPERATURE:  
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)  
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER  
101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com