




PRODUCT DESCRIPTION

Sweeping metal accents links create classic curves on a minimalist chandelier. Available in hand-rubbed Chestnut Bronze or elegant Gold Leaf finishes. Add crystal accents to elevate the design for a more extravagant glamour. The design manages to evoke French Country charm and enchants any room it illuminates.

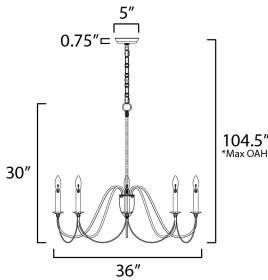

*max overall height

MEASUREMENTS

DIMENSION : 36" L x 36" W x 30" H
 MAX OAH : 105.5" OAH
 CANOPY : 1.14" H x 5.1" L
 HANGING WEIGHT : 5.3 lb

LAMPING

INPUT VOLTAGE : 120V
 BULB : 8 x 60W Incandescent E12 Candelabra , 480W Total
 BULB INCLUDED : (Not Included)
 DIMMABLE : Y
 LIGHTING_DIRECTION : Up

FINISHES OPTION

- ☐ Chestnut Bronze
☒ Gold Leaf

GLASS

Crystal CRY

MATERIAL

Iron & Crystal

RATINGS

cULus
 Dry Location



ADDITIONAL

INSTALL UP/DOWN: Up
 OPERATING TEMPERATURE:
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746
 EASTERN DISTRIBUTION CENTER
 101 GARDNER PARK | PEACHTREE CITY, GA 30269
 P. 626.956.4200 | F. 626.956.4225 | maximlighting.com