




PRODUCT DESCRIPTION

A web of fiberglass is bonded together with latex and stretched over steel frames, creating a 50's contemporary design. When illuminated, the fiber shows through the soft fabric and adds texture to this unique look.

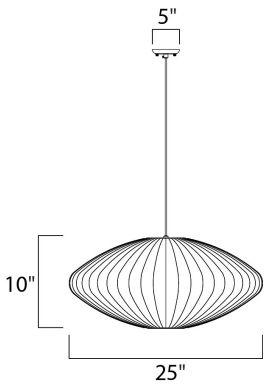

 
MEASUREMENTS

- DIMENSION : 25" L x 25" W x 10" H
MAX OAH : 130" OAH
CANOPY : 5" W x 1.25" H x 5" L
HANGING WEIGHT : 4.41 lb

LAMPING

- INPUT VOLTAGE : 120V
BULB : 1 x 60W Incandescent E26 Medium , 60W Total
BULB INCLUDED : (Not Included)
DIMMABLE : Yes

FINISHES OPTION



MATERIAL

Steel, Imitation Silk

RATINGS

cETLus
Dry Location



ADDITIONAL

SLOPE: 120
OPERATING TEMPERATURE:
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746
EASTERN DISTRIBUTION CENTER
4200 SHIRLEY DR. | ATLANTA, GA 30336
P. 626.956.4200 | F. 626.956.4225 | maximlighting.com