




PRODUCT DESCRIPTION

A modest frame of steel tubing gently bends to support a cluster of Clear Seedy bell-shaped glass. Similarly the bobeches and other metal accents echo that traditional bell shape creating an instant classic. An easy choice with transitional appeal, choose from a variety of complimentary finishes including matte Black, Heritage Brass or Satin Nickel.

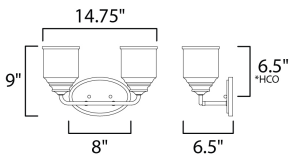

*height from center of outlet to the top of the fixture

MEASUREMENTS

DIMENSION : 14.75" W x 9" H x 6.5" Ext
BACK PLATE : 8" W x 5" H x 6.5" HCO
HANGING WEIGHT : 2.95 lb

LAMPING

INPUT VOLTAGE : 120V
BULB : 2 x 60W Incandescent E26 Medium , 120W Total
BULB INCLUDED : (Not Included)
DIMMABLE : Y
LIGHTING_DIRECTION : Omni

FINISHES OPTION

-  Black
-  Heritage
-  Satin Nickel

GLASS

Seedy CD

MATERIAL

Steel + Glass

RATINGS

cETLus
Damp Location



ADDITIONAL

INSTALL UP/DOWN: Up/Down
SLOPE: 30
OPERATING TEMPERATURE:
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746
EASTERN DISTRIBUTION CENTER
101 GARDNER PARK | PEACHTREE CITY, GA 30269
P. 626.956.4200 | F. 626.956.4225 | maximlighting.com