




PRODUCT DESCRIPTION

A modest frame of steel tubing gently bends to support a cluster of Clear Seedy bell-shaped glass. Similarly the bobeches and other metal accents echo that traditional bell shape creating an instant classic. An easy choice with transitional appeal, choose from a variety of complimentary finishes including matte Black, Heritage Brass or Satin Nickel.

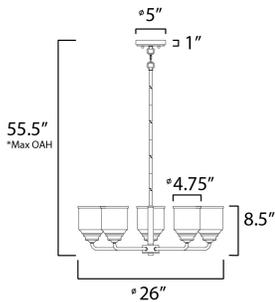

*max overall height

MEASUREMENTS

DIMENSION : 26" L x 26" W x 8.5" H
 MAX OAH : 55.5" OAH
 CANOPY : 5" W x 1" H x 5" L
 HANGING WEIGHT : 7.05 lb

LAMPING

INPUT VOLTAGE : 120V
 BULB : 5 x 60W Incandescent E26 Medium , 300W Total
 BULB INCLUDED : (Not Included)
 DIMMABLE : Y

FINISHES OPTION

-  Black
-  Heritage
-  Satin Nickel

GLASS

Seedy CD

MATERIAL

Steel + Glass

RATINGS

cETLus
 Dry Location



ADDITIONAL

ADJUSTABLE
 SLOPE: 70
 OPERATING TEMPERATURE:
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER
 101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com