




**PRODUCT DESCRIPTION**

Tasteful globes constructed of metal and glass halves are combined and suspended by an arc-shaped yoke structure. The top dome of robust steel support lower halves of Satin White glass shades that twist lock on for convenience of installation and maintenance. Available in Matte Black with contrasting Weathered Brass or Satin Nickel with Satin Brass two tone finishes, the series includes a full range of products including flush mount, semi-flush mount, single and multi-pendant configurations, and spec-worthy sconces. This attractive design is sure to enhance your projects most needed spaces with an enduring appeal to the design that works in a variety of aesthetics.

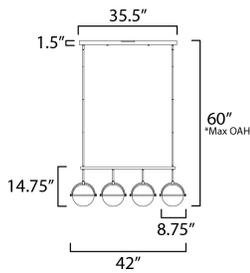

\*max overall height

**MEASUREMENTS**

DIMENSION : 42" L x 8.75" W x 14.75" H  
 MAX OAH : 60" OAH  
 CANOPY : 4.75" W x 1.5" H x 35.5" L  
 HANGING WEIGHT : 18.43 lb

**LAMPING**

INPUT VOLTAGE : 120V  
 BULB : 4 x 60W Incandescent E26 Medium , 240W Total  
 BULB INCLUDED : (Not Included)  
 DIMMABLE : Y  
 LIGHTING\_DIRECTION : Down

**FINISHES OPTION**

-  Black/Weathered Brass
-  Satin Nickel / Satin Brass

**GLASS**

Satin White SW

**MATERIAL**

Steel, Glass

**RATINGS**

cETLus  
 Dry Location



**ADDITIONAL**

INSTALL UP/DOWN: Down  
 OPERATING TEMPERATURE:  
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)  
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER  
 101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com