




PRODUCT DESCRIPTION

Spherical dual shades constructed of woven string in two tone finish combinations, Natural with White inner and Chocolate with White inner. Shades are treated for weather resistance and are U.L. approved for damp location which make them perfect for outdoor living spaces.

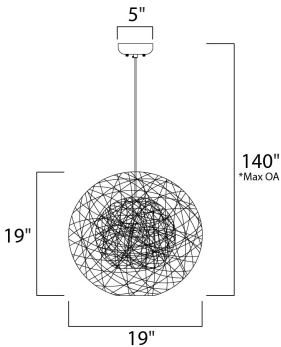

*max overall height

MEASUREMENTS

- DIMENSION : 19" L x 19" W x 19" H
- MAX OAH : 140" OAH
- CANOPY : 5" W x 1.25" H x 5" L
- HANGING WEIGHT : 2.87 lb

LAMPING

- INPUT VOLTAGE : 120V
- BULB : 1 x 60W Incandescent E26 Medium , 60W Total
- BULB INCLUDED : (Not Included)
- DIMMABLE : Yes

FINISHES OPTION

- Chocolate
- Natural

MATERIAL

Hemp Twine, Steel

RATINGS

cETLus
Damp Location



ADDITIONAL

SLOPE: 120
OPERATING TEMPERATURE:
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746
EASTERN DISTRIBUTION CENTER
4200 SHIRLEY DR. | ATLANTA, GA 30336
P. 626.956.4200 | F. 626.956.4225 | maximlighting.com