




PRODUCT DESCRIPTION

Unique and dramatic pendants are created using solid Clear glass rods that fit into castings finished in Polished Nickel. This design is a creative mix of modern and classic which has a broad universal appeal.

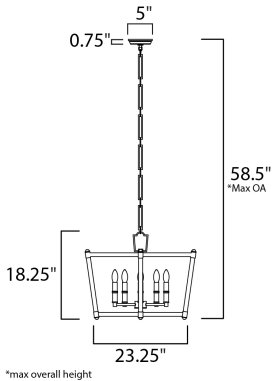

MEASUREMENTS

- DIMENSION : 19.25" L x 23.25" W x 18.25" H
MAX OAH : 58.5" OAH
CANOPY : 5" W x 1" H x 5" L
HANGING WEIGHT : 9.7 lb

LAMPING

- INPUT VOLTAGE : 120V
BULB : 5 x 60W Incandescent E12 Candelabra , 300W Total
BULB INCLUDED : (Not Included)

FINISHES OPTION

-  Polished Nickel

GLASS

- Clear CL

MATERIAL

- Steel, Glass

RATINGS

- cULus
Dry Location



ADDITIONAL

- ADJUSTABLE
SLOPE: 30
OPERATING TEMPERATURE:
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
253 NORTH VINELAND AVE | CITY OF INDUSTRY, GA 91746
EASTERN DISTRIBUTION CENTER
4200 SHIRLEY DR. | ATLANTA, GA 30336
P. 626.956.4200 | F. 626.956.4225 | maximlighting.com