




PRODUCT DESCRIPTION

Low sloping arms of rectilinear tubing is finished in a variety of options that include Satin Nickel, Oil Rubbed Bronze, Matte Black, and a contemporary Satin Brass finish. Tall, cylindrical Satin White glass shades soften the light source within. Offered in a variety of configurations that include chandeliers, sconces, and a semi-flush pendant that may be used as a foyer pendant, has become a proven popular choice among builders.

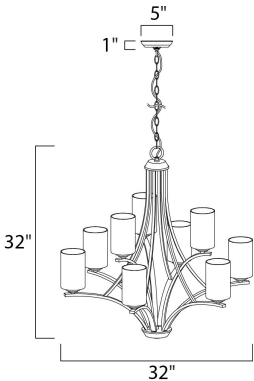

MEASUREMENTS

DIMENSION : 32" L x 32" W x 32" H
MAX OAH : 108" OAH
CANOPY : 5" W x 0.78" H x 5" L
HANGING WEIGHT : 15.75 lb

LAMPING

INPUT VOLTAGE : 120V
BULB : 9 x 60W Incandescent E26 Medium , 540W Total
BULB INCLUDED : (Not Included)
DIMMABLE : Y

FINISHES OPTION

- Black
- Oil Rubbed Bronze
- Satin Brass
- Satin Nickel

GLASS

Satin White SW

MATERIAL

Steel, Glass

RATINGS

cETLus
Dry Location



ADDITIONAL

SLOPE: 70
OPERATING TEMPERATURE:
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746
EASTERN DISTRIBUTION CENTER
101 GARDNER PARK | PEACHTREE CITY, GA 30269
P. 626.956.4200 | F. 626.956.4225 | maximlighting.com