




PRODUCT DESCRIPTION

The timeless Empire chandelier shape styled in timeworn, natural finishes uses durable steel in a Driftwood finish that includes a spherical ornament in matching finish. The arms curve steeply, swept lower than the chandelier's center, emphasizing the chandelier's height while mitered angles at its top accentuate the thickness of the barrel-like planks. Exposed candelabra lamps on Anthracite candle covers adding texture and contrast. The result of the organic wood tones reduces the formality of the classical shape making the elegance of this design more inviting.

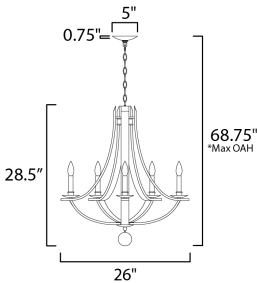

*max overall height

MEASUREMENTS

DIMENSION : 26" L x 26" W x 28.5" H
MAX OAH : 68.75" OAH
CANOPY : 5" W x 0.75" H x 5" L
HANGING WEIGHT : 17.16 lb

LAMPING

INPUT VOLTAGE : 120V
BULB : 5 x 60W Incandescent E12 Candelabra , 300W Total
BULB INCLUDED : (Not Included)
DIMMABLE : Y

FINISHES OPTION

Driftwood/Anthracite

MATERIAL

Steel

RATINGS

cETLus
Dry Location



ADDITIONAL

OPERATING TEMPERATURE:
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746
EASTERN DISTRIBUTION CENTER
101 GARDNER PARK | PEACHTREE CITY, GA 30269
P. 626.956.4200 | F. 626.956.4225 | maximlighting.com