




PRODUCT DESCRIPTION

Traditional fonts of Polished Nickel support Clear glass shades reminiscent of Colonial times. This ageless design has upscale appeal at an attractive price.

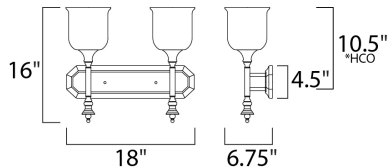

*height from center of outlet to the top of the fixture

MEASUREMENTS

DIMENSION : 18" W x 16" H x 6.75" Ext
 BACK PLATE : 18" W 10.5" HCO
 CANOPY : 4.5" H
 HANGING WEIGHT : 6.84 lb

LAMPING

INPUT VOLTAGE : 120V
 BULB : 2 x 60W Incandescent E26 Medium , 120W Total
 BULB INCLUDED : (Not Included)
 DIMMABLE : Yes

FINISHES OPTION

 Polished Nickel

GLASS

Clear CL

MATERIAL

Steel, Glass

RATINGS

cETLus
 Damp Location



ADDITIONAL

INSTALL UP/DOWN: Up/Down
 OPERATING TEMPERATURE:
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER
 4200 SHIRLEY DR. | ATLANTA, GA 30336

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com