




**PRODUCT DESCRIPTION**

Traditional fonts of Polished Nickel support Clear glass shades reminiscent of Colonial times. This ageless design has upscale appeal at an attractive price.

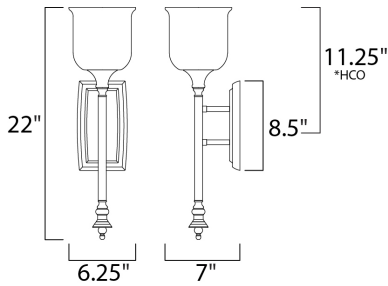

\*height from center of outlet to the top of the fixture

**MEASUREMENTS**

- DIMENSION : 6.25" W x 22" H x 7" Ext
- MAX OAH : 8.5" W
- CANOPY : 4.75" H
- HANGING WEIGHT : 3.41 lb

**LAMPING**

- INPUT VOLTAGE : 120V
- BULB : 1 x 60W Incandescent E26 Medium , 60W Total
- BULB INCLUDED : (Not Included)
- DIMMABLE : Yes

**FINISHES OPTION**

- Polished Nickel

**GLASS**

Clear CL

**MATERIAL**

Steel, Glass

**RATINGS**

cETLus  
Damp Location



**ADDITIONAL**

INSTALL UP/DOWN: Up/Down  
OPERATING TEMPERATURE:  
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



**WESTERN DISTRIBUTION CENTER (HEADQUARTER)**  
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

**EASTERN DISTRIBUTION CENTER**  
4200 SHIRLEY DR. | ATLANTA, GA 30336

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com