



PRODUCT DESCRIPTION


Metal shades finished in a warm Heritage Brass are accented with Dark Bronze metal straps and Tobacco Brown leather wrapped details. Recessed within the metal shades, a frosted glass diffuser softly casts the LED light source within. Paddles on every shade allow the light to easily be directed upward or downwards. With the accompanying wall sconce in the collection, a touch switch is located on its top and the convenient paddle at its end allows you to direct the light source where needed. Tasteful and timeless, the reimagined classic metal drum shades are elevated with technology and convenient features. Perfect for entries, eating areas, and bedside applications.

MEASUREMENTS

DIMENSION : 48" L x 24" W x 6.25" H
 MAX OAH : 50.5" OAH
 CANOPY : 5.5" W x 0.75" H x 5.5" L
 HANGING WEIGHT : 15.114 lb

LAMPING

INPUT VOLTAGE : 120V
 LUMENS : 3,000 Rated (2,800 Del.)
 BULB : 6 x 6W LED AC Integrated , 36W Total
 BULB INCLUDED : (Integrated)
 DIMMABLE :
 CRI : 90 CRI
 COLOR_TEMP : 3000K
 LIGHTING_DIRECTION : Directional

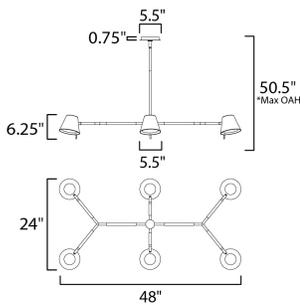

*max overall height

FINISHES OPTION

Dark Bronze, Leather, Heritage Brass

MATERIAL

Steel, Acrylic

RATINGS

Dry Location



ADDITIONAL

OPERATING TEMPERATURE:
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER
 101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com