




PRODUCT DESCRIPTION

Dramatically modern, individually supported rods run through a series of flat circular disks adding interest to the elongated adjustable arms that can be configured according to how you choose to position them. Finished in Naturally Aged Brass and Matte Black finishes, the frames terminate at their ends with LED tubular lamps supplied and shrouded in long cylindrical glass shades secured with pins at the fixture's sockets. The characteristic details and warm filament light source add industrial flair making the collection's modern configuration suitable to a wider array of transitional styling.

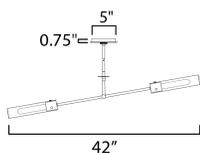

MEASUREMENTS

- DIMENSION : 42" L x 42" W x 7.75" H
- MAX OAH : 51" OAH
- CANOPY : 5" W x 0.75" H x 5" L
- HANGING WEIGHT : 5 lb

LAMPING

- INPUT VOLTAGE : 120V
- LUMENS : 1,200 Rated (960 Del.)
- BULB : 2 x 6W LED E26 Medium , 12W Total
- BULB INCLUDED : (Included)
- DIMMABLE : Y
- CRI : 90 CRI
- COLOR_TEMP : 2700K

FINISHES OPTION

- Black
- Natural Aged Brass

GLASS

Clear CL

MATERIAL

Steel, Glass

RATINGS

cETLus
Dry Location



ADDITIONAL

RATED LIFE 25000 Hours
OPERATING TEMPERATURE:
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746
EASTERN DISTRIBUTION CENTER
101 GARDNER PARK | PEACHTREE CITY, GA 30269
P. 626.956.4200 | F. 626.956.4225 | maximlighting.com