




PRODUCT DESCRIPTION

Opal White glass balls suspend from a wave like metal arm finished in Polished Chrome. The clean contemporary design provides excellent illumination and classic design appeal. Brackets can be installed either glass up or down.

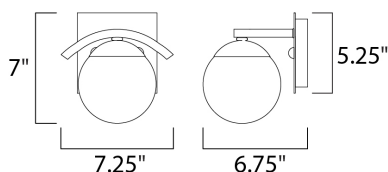

MEASUREMENTS

DIMENSION : 7.25" W x 7" H x 6.75" Ext
MAX OAH : 5.25" W x 5.25" H
HANGING WEIGHT : 3.2 lb

LAMPING

INPUT VOLTAGE : 120V
LUMENS : 490 Rated
BULB : 1 x 40W Xenon G9 , 40W Total
BULB INCLUDED : (Included)
DIMMABLE : Yes

FINISHES OPTION

 Polished Chrome

GLASS

White WT

MATERIAL

Glass, Steel

RATINGS

cETLus
Wet Location



ADDITIONAL

INSTALL UP/DOWN: Up/Down
RATED LIFE 2000 Hours
OPERATING TEMPERATURE:
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER
4200 SHIRLEY DR. | ATLANTA, GA 30336

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com