



PRODUCT DESCRIPTION

This fashionable modern chandelier combines solid wood shades with warm bronze and brass tones. Posing with arms akimbo, a combination of walnut stained oak and Satin White glass shades creates a transitional statement in mixed materials while also providing pleasant glare-free lighting. A coordinating swing arm wall sconce extends horizontally using an attractive and sturdy arm structure. This collection blends with a variety of styles thanks to its two-tone Dark Bronze and Antique Brass finish and the natural tones of the wooden shades. LED lamps are conveniently included with the fixtures as an all-inclusive package, making them energy efficient as well.

FINISHES OPTION

Dark Bronze/Antique Brass

MATERIAL

Steel, Glass, Wood

RATINGS

cETLus
Dry Location



ADDITIONAL


RATED LIFE 25000 Hours
OPERATING TEMPERATURE:
-20°C (-4°F), 40°C (104°F)

MEASUREMENTS

DIMENSION : 14.5" L x 21.75" W x 24.25" H
MAX OAH : 67.25" OAH
CANOPY : 6" W x 1" H x 6" L
HANGING WEIGHT : 7.94 lb

LAMPING

INPUT VOLTAGE : 120V
LUMENS : 2,400 Rated (1,650 Del.)
BULB : 4 x 6W LED E26 Medium , 24W Total
BULB INCLUDED : (Included)
DIMMABLE : Y
CRI : 90 CRI
COLOR_TEMP : 3000K

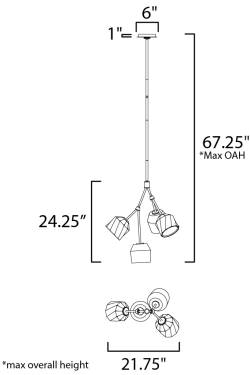

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746
EASTERN DISTRIBUTION CENTER
101 GARDNER PARK | PEACHTREE CITY, GA 30269
P. 626.956.4200 | F. 626.956.4225 | maximlighting.com