




PRODUCT DESCRIPTION

This fashionable modern chandelier combines solid wood shades with warm bronze and brass tones. Posing with arms akimbo, a combination of walnut stained oak and Satin White glass shades creates a transitional statement in mixed materials while also providing pleasant glare-free lighting. A coordinating swing arm wall sconce extends horizontally using an attractive and sturdy arm structure. This collection blends with a variety of styles thanks to its two-tone Dark Bronze and Antique Brass finish and the natural tones of the wooden shades. LED lamps are conveniently included with the fixtures as an all-inclusive package, making them energy efficient as well.

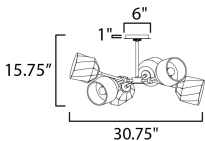

MEASUREMENTS

- DIMENSION : 30.75" L x 30.75" W x 15.75" H
- MAX OAH : 15.75" OAH
- CANOPY : 6" W x 1" H x 6" L
- HANGING WEIGHT : 10.58 lb

LAMPING

- INPUT VOLTAGE : 120V
- LUMENS : 3,600 Rated (2,500 Del.)
- BULB : 6 x 6W LED E26 Medium , 36W Total
- BULB INCLUDED : (Included)
- DIMMABLE : Y
- CRI : 90 CRI
- COLOR_TEMP : 3000K

FINISHES OPTION

-  Dark Bronze/Antique Brass

MATERIAL

Steel, Glass, Wood

RATINGS

cETLus
Dry Location



ADDITIONAL

RATED LIFE 25000 Hours
OPERATING TEMPERATURE:
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746
EASTERN DISTRIBUTION CENTER
101 GARDNER PARK | PEACHTREE CITY, GA 30269
P. 626.956.4200 | F. 626.956.4225 | maximlighting.com