




PRODUCT DESCRIPTION

A fun and unique design the features numerous concentric rings finished Black on the outside and Gold on the inside that pivot from a center point. The rings can be configured from completely flat to full repeated symmetry and anything in between to allow flexibility in the design.

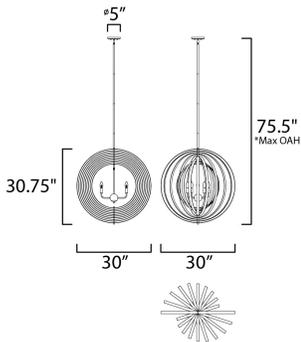

*max overall height

MEASUREMENTS

- DIMENSION : 30" L x 30" W x 31" H
- MAX OAH : 75.5" OAH
- CANOPY : 5" W x 0.75" H x 5" L
- HANGING WEIGHT : 20.7 lb

LAMPING

- INPUT VOLTAGE : 120V
- BULB : 5 x 60W Incandescent E12 Candelabra , 300W Total
- BULB INCLUDED : (Not Included)
- DIMMABLE : Yes

FINISHES OPTION

-  Black / Gold
-  Polished Nickel / Black

MATERIAL

Steel

RATINGS

cULus
Dry Location



ADDITIONAL

ADJUSTABLE
SLOPE: 90
OPERATING TEMPERATURE:
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746
EASTERN DISTRIBUTION CENTER
4200 SHIRLEY DR. | ATLANTA, GA 30336
P. 626.956.4200 | F. 626.956.4225 | maximlighting.com