




**PRODUCT DESCRIPTION**

A fun and unique design the features numerous concentric rings finished Black on the outside and Gold on the inside that pivot from a center point. The rings can be configured from completely flat to full repeated symmetry and anything in between to allow flexibility in the design.

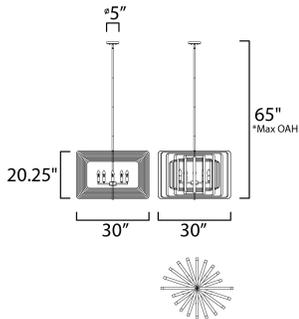

\*max overall height

**MEASUREMENTS**

- DIMENSION : 30" L x 30" W x 20.75" H
- MAX OAH : 65" OAH
- CANOPY : 5" W x 0.75" H x 5" L
- HANGING WEIGHT : 20.7 lb

**LAMPING**

- INPUT VOLTAGE : 120V
- BULB : 5 x 60W Incandescent E12 Candelabra , 300W Total
- BULB INCLUDED : (Not Included)
- DIMMABLE : Yes

**FINISHES OPTION**

-  Black / Gold
-  Polished Nickel / Black

**MATERIAL**

Steel

**RATINGS**

cULus  
Dry Location



**ADDITIONAL**

ADJUSTABLE  
SLOPE: 90  
OPERATING TEMPERATURE:  
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



**WESTERN DISTRIBUTION CENTER (HEADQUARTER)**  
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

**EASTERN DISTRIBUTION CENTER**  
4200 SHIRLEY DR. | ATLANTA, GA 30336

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com