



PRODUCT DESCRIPTION


Effortlessly elegant, the biophilic details that adorn this classic chandelier transports you to an oasis indoors. The design, whether brilliantly gilt in Gold Leaf or hand painted in a dramatically textural Anthracite finish, exudes a timeless quality that is sure to please. The graceful form of these fixtures is constructed of slender metal tubes that sprout from a spherical collector at the center and Off-White metal candle covers that are designed to last.

MEASUREMENTS

DIMENSION : 10.25" W x 15.75" H x 6" Ext
 MAX OAH : 4.75" W x 4.75" H
 HANGING WEIGHT : 2.42 lb

LAMPING

INPUT VOLTAGE : 120V
 BULB : 2 x 60W Incandescent E12 Candelabra , 120W Total
 BULB INCLUDED : (Not Included)
 DIMMABLE : Y
 LIGHTING_DIRECTION : Up

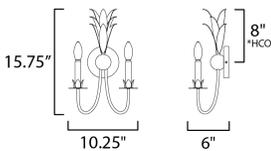

*height from center of outlet to the top of the fixture

FINISHES OPTION

-  Anthracite
-  Gold Leaf

MATERIAL

Steel

RATINGS

cETLus
 Damp Location



ADDITIONAL

INSTALL UP/DOWN: Down
 OPERATING TEMPERATURE:
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER
 101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com